



PRODUCT DESCRIPTION


Using our proprietary Vivex material developed for use in harsh climates, the Nassau series presents Coastal styling, historical in design, made of an appropriately specified material for just this application. Available in your choice of solid Black or a cool combination of White with Black accents, the lanterns protect clusters of candelabras with clear glass panels. Add filament lamps to the lanterns to complete the look.

MEASUREMENTS

DIMENSION : 7.5" W x 21.25" H x 8.5" Ext
 BACK PLATE : 7.5" W x 8.75" H x 12" HCO
 HANGING WEIGHT : 7.986 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 2 x 60W Incandescent E12 Candelabra , 120W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Y

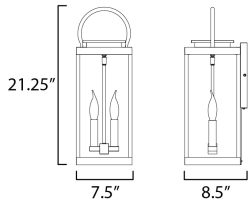

FINISHES OPTION



GLASS

Clear CL

MATERIAL

EPMM Vivex, Glass

RATINGS

cETLus
 Wet Location



ADDITIONAL

INSTALL UP/DOWN: Down
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com