



PRODUCT DESCRIPTION


Tasteful details on this series of low-profile Vivex sconces and flush mounts adds a stylish touch to functional spaces. Finished in a two-tone Black and Gold combination, this Vivex series is engineered to withstand harsher climates adding fashionable flare to a necessary lighting element. The Gold rivet details at its corners are not just decorative, but structurally secure an outer shell that seals its internal LED housing from water intrusion. The applications of the flush mount and slim sconces provide dimensional convenience and accessibility for limited spaces or hallways regulated by ADA requirements.

MEASUREMENTS

DIMENSION : 12" W x 3.5" H
 MAX OAH : 11" W x 3.25" H
 HANGING WEIGHT : 3 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 1,920 Rated (1,200 Del.)
 BULB : 1 x 29W LED AC Integrated , 29W Total
 BULB INCLUDED : (Integrated)
 DIMMABLE : Y
 CRI : 90 CRI
 COLOR_TEMP : 3000K

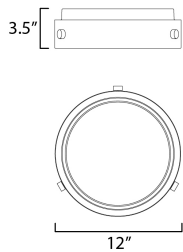

FINISHES OPTION

 Black / Antique Brass

MATERIAL

EPMM, Aluminum

RATINGS

cETLus
 Damp Location



ADDITIONAL

RATED LIFE 35000 Hours
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com