




PRODUCT DESCRIPTION

A rectangular cast frame cradles a cylinder of clear Bubble Glass that is perfect for the modern home exterior. The top housing conceals a high power LED light module with excellent color rendering as well as efficient lumens per watt. All of this at an unbelievable price.

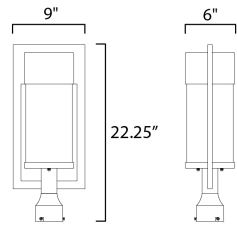

MEASUREMENTS

DIMENSION : 9" W x 22.25" H x 6" Ext
 HANGING WEIGHT : 7.71 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 980 Rated (210 Del.)
 BULB : 1 x 12W LED PCB Integrated , 12W Total
 BULB INCLUDED : (Integrated)
 DIMMABLE : Y
 CRI : 90 CRI
 COLOR_TEMP : 3000K
 LIGHTING_DIRECTION : Down

FINISHES OPTION

 Black

GLASS

Bubble Glass BG

MATERIAL

Aluminum + Glass

RATINGS

cETLus
 Wet Location



ADDITIONAL

INSTALL UP/DOWN: Down
 RATED LIFE 50000 Hours
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com