

# TRIM | 0-10V LED FLUSH MOUNT

**57670 | 57880 | 57881 | 57882 | 57883 | 57884 | 57885 | 57894 | 57895**

- Die Cast Aluminum
- Size options between 5", 7", 9", 11" and 16"
- Ultra-thin 1/2" height with less than 1/4" trim
- Available in 3000k (Other CCT available on request)
- Available in White (WT), Black (BK), Polished Chrome (PC) and Satin Nickel (SN)
- Easy to install: fits in 3-0 and 4-0 Outlet Box
- Suitable for Wet Location, for use on ceilings outdoor and above showers
- For Dimming Information, see Dimmer Compatibility Chart


Job Name : \_\_\_\_\_  
 Job Type : \_\_\_\_\_  
 Quantity : \_\_\_\_\_  
 Comments : \_\_\_\_\_



## PRODUCT DESCRIPTION

Thin discs of evenly illuminated LED create the impression of recessed lighting. The die-cast aluminum housings are available in White, Black, Satin Nickel, and Polished Chrome all with a thoughtfully recessed White polycarbonate diffuser. High efficiency and good color rendering make this a perfect choice for your next project. Use the optional pendant adapter to convert any size to a hanging fixture.

## FINISH OPTIONS

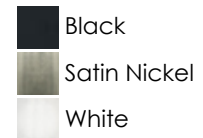

## DIFFUSER

White Polycarbonate

## MATERIAL

Polycarbonate + Aluminum

## AVAILABLE SIZES

5" | 7" | 9" | 16"

## RATINGS & CERTIFICATIONS

cETLus  
 Wet Location  
 Energy Star  
 JA8 Listed




## ADDITIONAL

RATED LIFE 50000 Hours  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

PHOTOMETRIC:  
 Report Found Online

## MEASUREMENTS

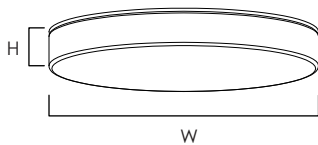

MODEL	DIMENSION
57670	16" W x 1.5"H
57880	5" W x 0.5"H
57881	5" W x 0.5"H
57882	7" W x 0.5"H
57883	7" W x 0.5"H
57884	9" W x 0.5"H
57885	9" W x 0.5"H
*57894	7" W x 0.5"H
*57895	7" W x 0.5"H

## LAMPING

MODEL	WATTAGE & TYPE	COLOR TEMP	CRI	INPUT	DIMMABLE	LUMENS	
						RATED	DEL
57670	25W LED (Integrated)	3000K	90+	120V	ELV	2250	1750
57880	12.5W LED (Integrated)	3000K	90+	120-277V	0-10V	950	875
57881	12.5W LED (Integrated)	4000K	90+	120-277V	0-10V	920	875
57882	15W LED (Integrated)	3000K	90+	120-277V	0-10V	1100	1050
57883	15W LED (Integrated)	4000K	90+	120-277V	0-10V	1100	1050
57884	18W LED (Integrated)	3000K	90+	120-277V	0-10V	1280	1260
57885	18W LED (Integrated)	4000K	90+	120-277V	0-10V	1280	1260
* 57894	15W LED (Integrated)	3000K	90+	120-277V	0-10V	1100	1050
* 57895	15W LED (Integrated)	4000K	90+	120-277V	0-10V	1100	1050

\* EMERGENCY BACK-UP BATTERY INCLUDED  
 MINIMUM 15 HOURS FOR FULL CHARGE. LASTS 1.5 HOURS ON BATTERY

**WIRE LENGTH** 8"L

Always consult a qualified professional before installing any lighting products



**WESTERN DISTRIBUTION CENTER (HEADQUARTER)**  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

**EASTERN DISTRIBUTION CENTER**  
 4200 SHIRLEY DR. | ATLANTA, GA 30336

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com