

JEWEL | FANDELIGHT

61019BCBKGLD

- Beveled crystal accents set in reflective Gold clasps
- Two tone Black and Gold finish
- DC motor 6-speed fan with reverse function
- White Tunable LED transitions from warm 2700K to Daylight White
- Wall remote included
- Connect to Wifi for smart enabled function



Job Name : _____
 Job Type : _____
 Quantity : _____
 Comments : _____



ACCESSORIES (Sold Separately)



FCT6000WT

Wall Control



FCT6100WT

*Sold Separately

PRODUCT DESCRIPTION

An elegant fusion of function and fashion, this contemporary Fandelight features a bold Black band segmented by highly reflective plated Gold crystal settings. The settings support beveled crystal accents allowing natural and ambient light to glisten off its faceted surfaces. Encircled within this bejeweled band is an internal ring in Black that houses an LED light source directing ample light downward. Certainly a luxurious statement of modernity, the concept is further enhanced with our signature high performance, Wifi-enabled fans. Included with your purchase, there is a wall mounted remote control that allows function via switch or by Smart app. Elevate your space that needs a fan, with a Fan-delight!

- Always consult a qualified electrician before installing any lighting product
- Installation Requirements:
 Ceiling fan attaches to electrical junction box securely anchored and capable of withstanding at least 35 lbs

MEASUREMENTS


DIMENSION : 33" D x 23" H
 BLADES : 3 x 22"
 MAX OAH : 23" OAH
 CANOPY : 7.25" W x 2.75" H
 HANGING WEIGHT : 36.38 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 3,420 Rated (2,220 Del.)
 BULB : 30W PCB LED (intergrated)
 DIMMABLE : Remote or Wifi
 CRI : 90+ CRI
 COLOR TEMP : 2700-4000K

ENERGY INFORMATION AT HIGH SPEED

AIRFLOW : 2600 CFM
 ELECTRICITY USE : 27.3W
 AIRFLOW EFFICIENCY : 95 CFM / W

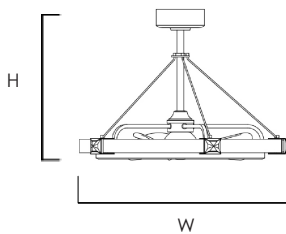

FINISHES OPTION

Black / Gold (BKGLD)

GLASS

Beveled Crystal BC

MATERIAL

Steel, Aluminum, ABS

RATINGS

cETLus
 Damp Location



INCLUDES

- Wall Mountable Remote Control
- 1 x 8" Downrod

DOWNROD OPTIONS

- 18" (FRD0118BK)
- 24" (FRD0124BK)
- 30" (FRD0130BK)
- 36" (FRD0136BK)

ADDITIONAL

OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)



WESTERN DISTRIBUTION CENTER (HEADQUARTER)

253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER

101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com