

# CUPOLA | CEILING FAN

**88801 | 88802**

- Available in Black, Bronze and Satin Nickel
- AC Wall control
- Dimmable

Job Name : \_\_\_\_\_  
 Job Type : \_\_\_\_\_  
 Quantity : \_\_\_\_\_  
 Comments : \_\_\_\_\_




Lamp light kit with domical glass



LED integrated dome

## PRODUCT DESCRIPTION

Sweeping arcs define this fan, designed for contemporary and refreshing upgrades. The central housing is domical, from which a trio of uniquely curved fan blades smoothly rotate. Available in Satin Nickel with Silver blades and Black with two-tone Walnut/Black blades, the Cupola also features an LED integrated dome shape or a 2 lamp light kit with a domical glass to create a perfect sphere.

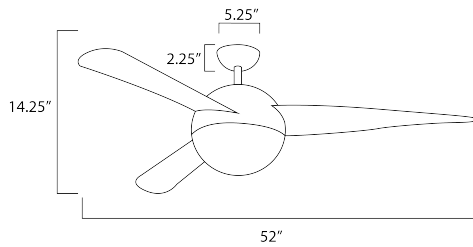

## MEASUREMENTS

MODEL	DIMENSION	CANOPY	MAX OAH	HANGING WEIGHT
88801	52"W x 12.80"H	5.25"W x 2.25"H	5.75"W x 22.75"H	17.28 lb
88802	52"W x 17.20"H	5.25"W x 2.25"H	5.75"W x 22.75"H	17.28 lb

## LAMPING

MODEL	BULB TYPE	LUMENS			ENERGY INFORMATION AT HIGH SPEEDS		
		CRI	INIT.	DEL.	CFM	EFFICIENCY	ELECTRICITY USE
88801	24W LED E26 120V	90+	2100	1680	3940 CFM	72 CFM / W	38W Dimmable
88802	24W LED E26 120V	90+	1500	1200	4116 CFM	72 CFM / W	39W Dimmable

## FINISHES OPTION

- Black (BK)
- Oil Rubbed Bronze (OI)
- Satin Nickel (SN)

## MATERIAL

Metal + ABS + glass

## RATINGS



## Downrod Options:

- 12" (FRD12)
- 18" (FRD18)
- 24" (FRD24)
- 36" (FRD36)
- 48" (FRD48)
- 60" (FRD60)
- 72" (FRD72)

## ADDITIONAL

- RATED LIFE 25000 Hours
- OPERATING TEMPERATURE: -20°C (-4°F), 40°C (104°F)
- Lamp Kit Available

Always consult a qualified electrician before installing any lighting product.



## WESTERN DISTRIBUTION CENTER (HEADQUARTER)

253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

## EASTERN DISTRIBUTION CENTER

101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com