

ULTRA SLIM | INDOOR CEILING FAN

88807

- Available in Black, Matte White and Satin Nickel
- AC Wall control
- Damp Location

Job Name : _____
 Job Type : _____
 Quantity : _____
 Comments : _____



Included:



Fan Control Only
 FCT88805WT



PRODUCT DESCRIPTION

With its small profile housing and elegant blade shape, the Ultra Slim provides an upgrade to indoor/outdoor fan options. Available in 3 different finishes: White, Nickel, and matte Black.

- Always consult a qualified electrician before installing any lighting product
- Installation Requirements:
 Ceiling fan attaches to electrical junction box securely anchored and capable of withstanding at least 35 lbs

FINISHES OPTION

- BK:** Black
- MW:** Matte White
- SN:** Satin Nickel

MATERIAL

Metal + ABS

RATINGS

cETLus
 Damp Location




Downrod Options:

- 12" (FRD12)
- 18" (FRD18)
- 24" (FRD24)
- 36" (FRD36)
- 48" (FRD48)
- 60" (FRD60)
- 72" (FRD72)

ADDITIONAL

OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

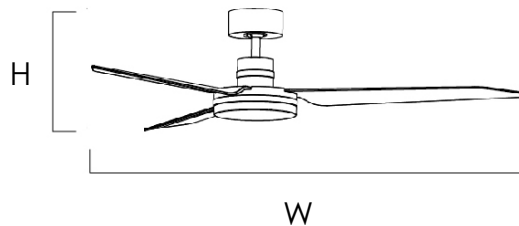

MEASUREMENTS

MODEL DIMENSION
 88807 52"W x 11"H

ENERGY INFORMATION AT HIGH SPEEDS

CFM	EFFICIENCY	ELECTRICITY USE	INPUT
3950 CFM	89 CFM / W	29W	120V



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269
 P. 626.956.4200 | F. 626.956.4225 | maximlighting.com