

Job Name : _____
 Job Type : _____
 Quantity : _____
 Comments : _____



ENERGY STAR OPTION
 *88816



REMOVE FAN ROD FOR HUGGER
 CONVERSION




AC Control
 FCT88801WT



* DC Control
 FCT88816WT

PRODUCT DESCRIPTION

Clean and contemporary, the Tanker ceiling fan is damp rated so whether it is a covered outdoor living space or any room indoor this sleek fan suits the application. Ditch the fan rod and convert to a hugger. Several lengths of extension rods allow you to use this fan no matter the ceiling height. Available in 2 different finishes: Satin Nickel, and matte Black.

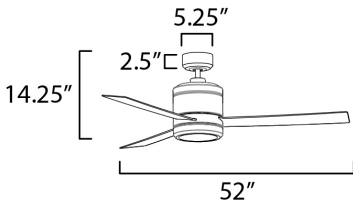


MEASUREMENTS

MODEL	DIMENSION	CANOPY	MAX OAH	HANGING WEIGHT
88805	52"W X 14.25"H	5.25"W X 2.5"H	5" W x 23" H	11.62 lb
88806	52"W X 14.25"H	5.25"W X 2.5"H	5" W x 23" H	11.62 lb
88816	52"W X 14.25"H	5.25"W X 2.5"H	5" W x 23" H	11.62 lb

LAMPING

MODEL	BULB TYPE	CRI	INIT.	DEL.	LUMENS	ENERGY INFORMATION AT HIGH SPEEDS	CFM	EFFICIENCY	ELECTRICITY USE
88805	DC 120V					4700 CFM	97 CFM / W		48W
88806	24W AC 120V*	90+	2100	1680	4700 CFM	97 CFM / W			60W
88816	24W DC 120V	90+	2100	1680	4700 CFM	333 CFM / W			13W

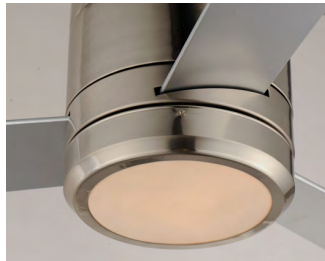

With Light Kit



Without Light Kit

FINISHES OPTION

- Black
- Satin Nickel

MATERIAL

Metal + ABS

RATINGS

cETLus
 Damp Location



ADDITIONAL

- OPERATING TEMPERATURE: -20°C (-4°F), 40°C (104°F)
- Light Kit Available

INCLUDED

*Wall Control

Downrod Options:

- 12" (FRD18)
- 18" (FRD24)
- 24" (FRD30)
- 36" (FRD36)
- 48" (FRD48)
- 60" (FRD60)
- 72" (FRD72)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)

253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER

101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com

CONTROLS

Easily adjust the speed and direction of your fan with a wall controller.

Adjust color temperature using a color tunable fan and wall control.



FCT88801WT
AC Wall Control
Light and Fan Speed
On/Off Rocker Switch for Light
Switch Included with:
88801, 88802, 88806



FCT88816WT
DC Wall Remote
Light and Fan Speed Control
Non-Dimming
Included with 88816



FCT88805WT
Fan Control ONLY
Three Speed Fan Control
Included with 88805 & 88807




FCT6000WT
FANDELIGHT™ Wall Remote
Magnetically Connect to Wall Plate
Light Dimming and CCT Tuning*
Battery Operated

*CCT tuning on select SKUs

OPTIONS



FCT 8881WT
AC Wall Control
Light Dimming and Fan Control
* Sold Separately
Compatible with:
88801, 88802, 88806, 89909

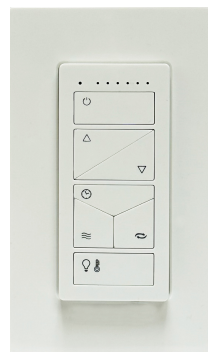

FCT6100WT
AC Wall Control
Light Dimming and Fan Control
* Sold Separately
Compatible with:
61002, 61006, 61011, 61012, 61014, 61019