

TRIO | CEILING FAN

89909

- 3000K Color Temp
- Available in Black, and Satin Nickel with Black Blades
- AC Wall control
- Dimmable
- Dry Location

Job Name : _____
 Job Type : _____
 Quantity : _____
 Comments : _____



*Sold Separately



AC Control
FCT8881WT



PRODUCT DESCRIPTION

A contemporary, yet transitional look at economical pricing, the Trio fan is finished in Satin Nickel with 3 straight fan blades in Black on one side and silver on the other side. The fan is powered by a wall control included as well as LED JA8 compliant bulbs also included.

- Always consult a qualified electrician before installing any lighting product
- Installation Requirements:
Ceiling fan attaches to electrical junction box securely anchored and capable of withstanding at least 35 lbs

FINISHES OPTION

- Black (FTBK)
- Satin Nickel / Black (FTSNBK)

GLASS

Frosted FT

MATERIAL

Steel

RATINGS

CULus
 Dry Location
 JA8 Bulb In




ADDITIONAL

OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Downrod Options:

- 12" (FRD12)
- 18" (FRD18)
- 24" (FRD24)
- 36" (FRD36)
- 48" (FRD48)
- 60" (FRD60)
- 72" (FRD72)

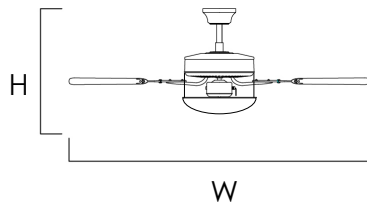

MEASUREMENTS

MODEL DIMENSION

89909 52"L x 52"W x 19"H

CANOPY

5.25"W x 2.5"H

MAX OAH

19"H

HANGING WEIGHT

13.89 lb

LAMPING

MODEL BULB TYPE

89909 2 x 9W LED 120V

LUMENS

CRI INIT. DEL.
 90+ 2100 1680

ENERGY INFORMATION AT HIGH SPEEDS

CFM EFFICIENCY ELECTRICITY USE
 4298 CFM 78 CFM / W 55W Dimmable



WESTERN DISTRIBUTION CENTER (HEADQUARTER)

253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER

101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com