




TANKLESS WATER HEATER

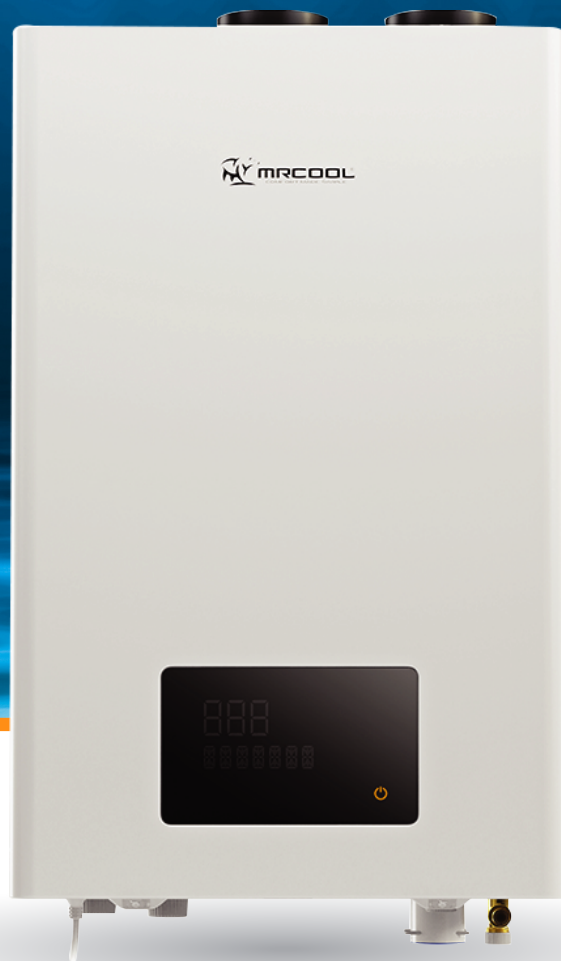

HIGH VOLUME & HIGH FLOW RATE



Large water supply can accommodate up to four home appliances at the same time.

STABLE TEMPERATURE CONTROL SYSTEM



Lead-free 304
Stainless steel
heat exchanger




Electronic
thermostatic
PCB



EDM BLDC
variable-speed
fan

MODEL SPECIFICATIONS

MODEL	MHWH199NCLU MHWH199NCNU
Rated Water Output Capacity	32 L/min
Nominal Power / Rated Heat Input	199,000 BTU/h
Suitable water pressure	70-140Psi
Gas inlet	NPT3/4
Cold inlet water	NPT3/4
Hot outlet water	NPT3/4
Flue pipe / Chimney diamete	2" or 3"
Rated Voltage / Freq	120V AC,60Hz
Efficiency	92%
Certification	CSA
N.W (kg)	31
G.W (kg)	33.5
Product dimensions (inches)	26.8" × 17.3" × 11.0"
Packaging dimensions (inches)	33.2" × 20.3" × 13.7"
Loading Qty (200P/400P/40HQ)	188/ 380/ 454

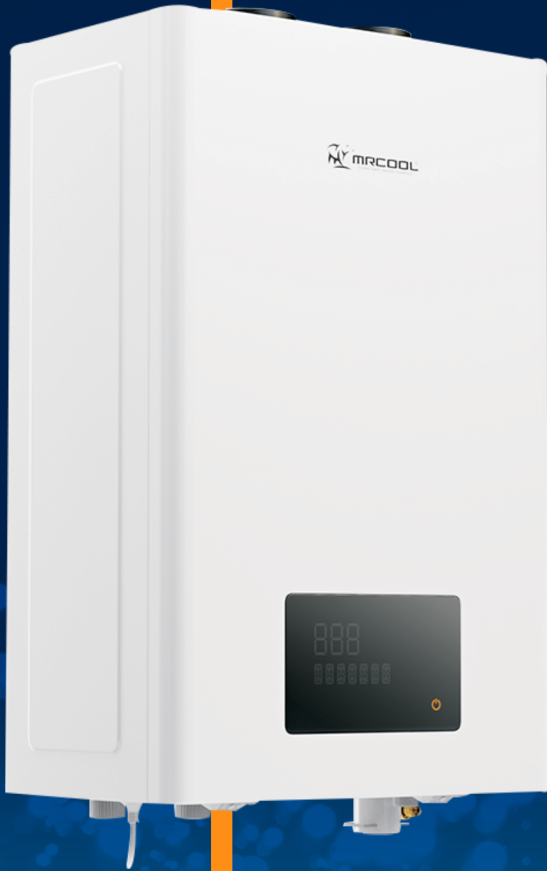

TANKLESS WATER HEATER

advanced engineering | high efficiency | environmental friendly

ULTRA-LOW NO_x & CO EMISSION TECHNOLOGY

Enjoy endless comfort running multiple hot water appliances at the same time. With the MRCOOL® Tankless Water Heater, waiting is no longer necessary. Instead, use that time to indulge and pamper yourself in a hot and relaxing tub or shower. Our Tankless Water Heater uses advanced technology to generate uniform heat, increase output, and create higher efficiency. It is also built with corrosion-resistant stainless steel for a better heat exchanger life, giving you peace of mind that your unit will last longer than a traditional water heater.



- ✓ Advanced Heat Exchanger Technology
- ✓ High Efficiency
- ✓ Eco-Friendly Premixed Burner
- ✓ Free of Lead & Toxic Materials
- ✓ Anti-Freeze Protection
- ✓ Meets SCAQMD Standards
- ✓ Smart Self-Adapting Temperature Regulation



48 Remington Way • Hickory, KY 42051 • 270.366.0457

*Display Images for demonstrative purposes only. Actual images during product use may vary.

www.mrcool.com