


PIG® Absorbent Mat Roll Refill for PIG® HazMat Quick-Response Spill Cart

MAT13401 Heavyweight, 15" x 90', 1 roll

Restock your HazMat Quick-Response High-Visibility Spill Cart with this replacement roll of PIG HazMat

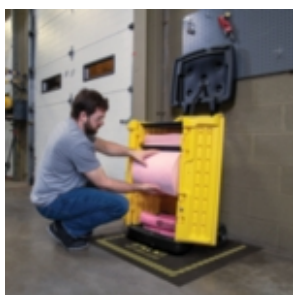

- Quickly mount this made-to-fit roll of HazMat inside your HazMat Quick-Response High-Visibility Spill Cart, as soon as your current roll runs out, and stay ready for HazMat spill response with pull-and-tear dispensing
- Safely grab from the PIG HazMat roll —made to absorb hazardous chemicals including acids, bases and corrosives — since the high-visibility pink color is quickly identifiable in a spill emergency.
- Caution: mats take on the properties of absorbed liquids, so always take proper precautions when handling saturated absorbents
- Note: this roll fits inside the current Quick-Response Spill Cart design; previous versions of the small caddy design do not accommodate this size of roll



Specifications

Absorbency Range	10 - 19.9 gal.
Dimensions	15" W x 90' L
Mat Weight	Heavyweight
Absorbency	Up to 11.9 gal. per roll
Absorbency per	Up to 11.9 gal. per roll
Brand	PIG
Color	Pink
Category	HazMat Chemical Absorbent Mat
Core Diameter	1.5"
Flammability Specifications	Flame Resistant - Will melt and self-extinguish
Floating	No
Fluid Absorbed	Acids; Bases; Unknowns
Indoor/Outdoor	Indoor Use
Incinerable	Yes

Perforated	Yes
Perforated Pattern	10" x 15" sections
Reusable	No
Static-Dissipative	No
Traffic	Light Foot Traffic
UV Resistant	No
Wringable	No
Sold as	1 roll
Weight	10 lbs.
# per Pallet	36
Composition	Polypropylene
UNSPSC	47131901
Pigalog® Page Number	Page 109

Metric Equivalent

Absorbency per	Up to 45 L per roll
Absorbency	Up to 45 L per roll
Weight	4.5 kg
Dimensions	38cm W x 27.4m L

Technical Information

Technical Documents

[PIG Hazardous Chemical Absorbents](#)

[Technical Data Sheet for PIG® HazMat Absorbents](#)

[29 CFR 1910.22\(a\)\(2\)](#)



One Pork Avenue • Tipton, PA 16684-0304

1-855-493-4647 • Fax: 1-800-621-7447 • newpig.com • hothogs@newpig.com