


# NOBLELIFT

INDUSTRIAL EQUIPMENT



## ACS44

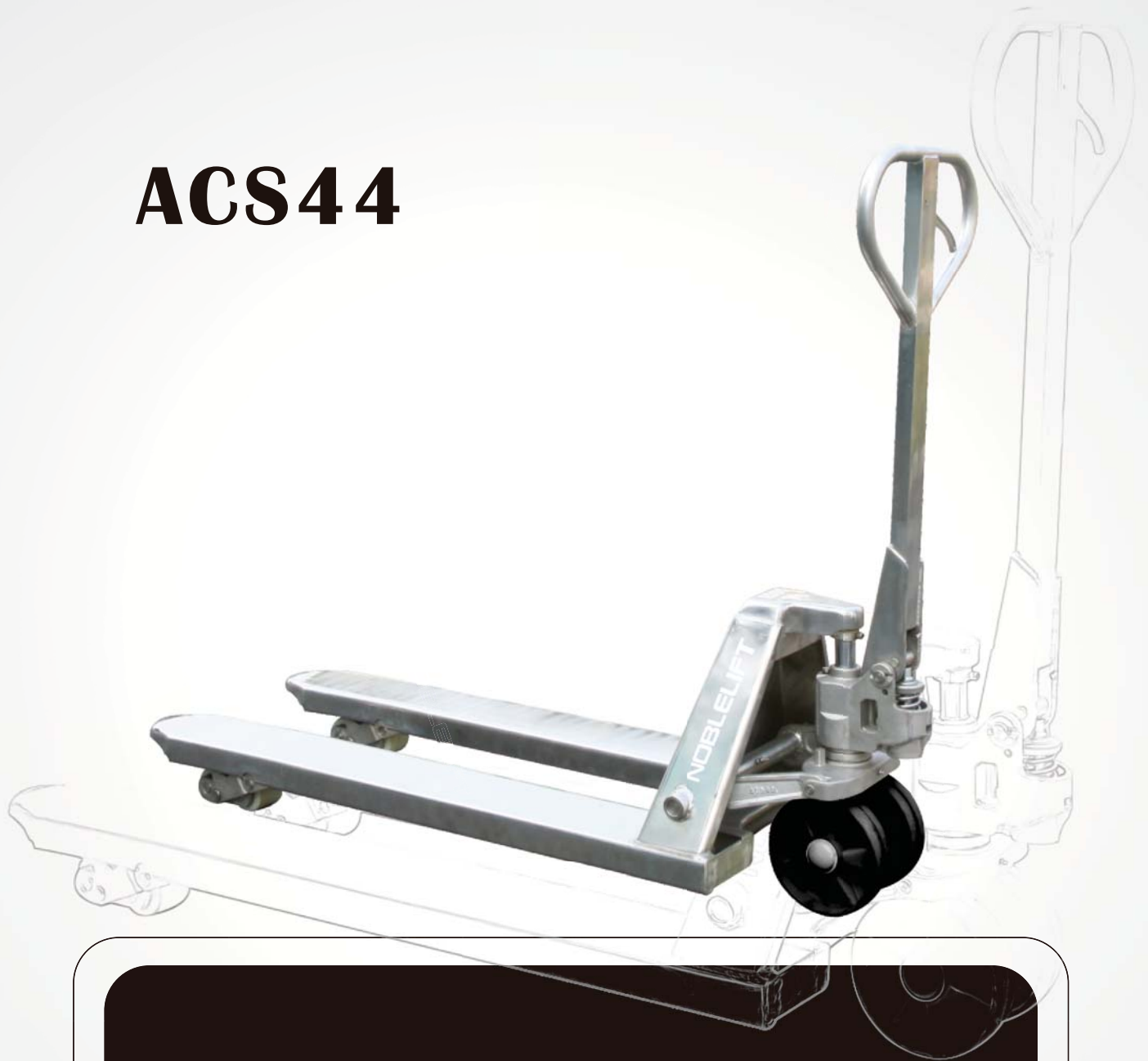

### **Stainless Steel Pallet Truck**

**Ideal for wet, corrosive and cold environments**

**Weight Capacity:  
4400 lbs.**

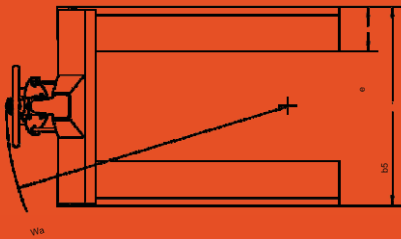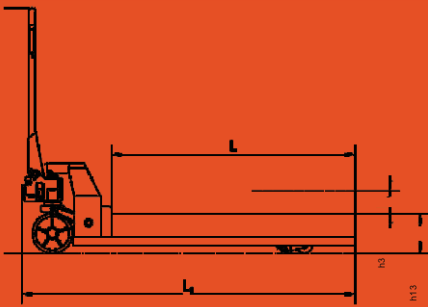

**ACS44**

**WHY CHOOSE BETWEEN PRICE AND QUALITY WHEN YOU CAN HAVE BOTH**

## Stainless Steel Pallet Truck

- All metal parts made completely stainless steel, including hydraulic pump, fork frame and handle.
- Ideal transport aid for applications in damp or harsh environments such as pharmaceutical, chemical, meat and fish plants.
- With pressure relief and overload valve to prevent pump damages from overloading.
- High quality nylon steering and load wheels as standard option for durability to extreme conditions .
- The enclosed fork tips ( for Aisi316 stainless truck only ) ensure there is no dead corner where corrosive spatters remain and damage the truck.

### AUTHORIZED DEALER

Item/Type		ACS44-2748-304	ACS44-2748-316
Capacity Q	lbs	4400	4400
Min. fork height h	Inch	2.95"	2.95"
Max. fork height h <sub>1</sub>	Inch	7.5	7.5
Steering wheel	Inch	φ 7×2	φ 7×2
Load roller Single	Inch	φ O.D:2.75 W:3.7	
Size of fork e*s	Inch	6.3×2.4	6.3×2.4
Width overall forks B	Inch	27	27
Fork length l	Inch	48	48
Stainless steel type	Inch	AISI304	AISI316

**Width overall Forks 21 available at request.**