

# NTH-126

BR/PAR38 Cone Track Head

Lamp: 250W BR40/PAR38 max.

Type \_\_\_\_\_

Project \_\_\_\_\_

Catalog No. \_\_\_\_\_

Notes \_\_\_\_\_

## PRODUCT DESCRIPTION

Streamlined conical BR/PAR track lighting fixtures with internal friction position hold.

## FEATURES

- Sleek, modern conical design
- Wire mesh decorative design feature
- High-strength stainless steel electrical contacts
- One or two circuit track capable
- Accepts LED lamps

## CONSTRUCTION

**Housing:** Conical shroud is 0.025" deep drawn steel construction with softened edges. Socket cup is a two-piece 0.10" injection molded high-heat rated assembly. Conical face completely houses BR/PAR light source for clean, finished appearance.

## ELECTRICAL

**Voltage:** 120V input

**Socket:** Medium base

**Lamp:** 250W BR40/PAR38 max. (not included)

## FINISH

Available in black and white finishes.

## ONE/TWO CIRCUIT CONVERSION

Positive contact (opposite neutral and ground contacts) is preset to "down" position at factory but may be raised to the higher position to install onto the second circuit of Nora Lighting NT-2300 series two-circuit track.

## LABELS AND LISTINGS

UL Listed




## PRODUCT IMAGES AND DIMENSIONS



**NTH-126B**  
Black Cone

**NTH-126W**  
White Cone

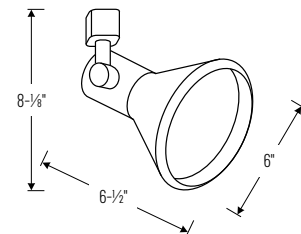

## BR/PAR38 Cone Track Head

Description

**NTH-126B** = Black Finish

**NTH-126W** = White Finish

Example: **NTH-126B** = BR40/PAR38 Cone, Black Finish