

NTS-615

6" Sloped Ceiling Reflector

Type _____

Project _____

Catalog No. _____

Notes _____

FEATURES

Trim: Precision spun 0.040 plastic with deep grooves to reduce aperture glare and white flange. Non-reflective painted finish.

Mounting: Trim includes two coil springs that clip and securely hold the trim into the housing when installed.

COMPATIBLE LAMP / HOUSINGS

75W BR30/PAR30 Max. ([NHIC-9260AT](#); [NHRIC-9260AT](#))


100W BR40/PAR38 Max. ([NHIC-926DW0AT](#))

LABELS AND LISTINGS

cULus Listed for Damp Locations when used with compatible housings.



PRODUCT IMAGES & DIMENSIONS

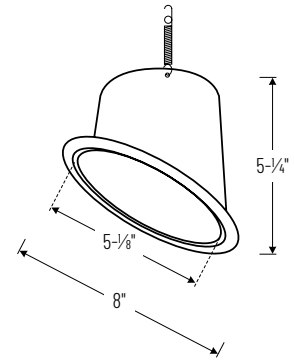

6" Sloped Ceiling Trim

Catalog No. _____

NTS-615W = 6" White Reflector with White Flange

Compatible Housings

Catalog No. _____

NHIC-926DW0AT = ICAT Sloped Double Wall New Construction / 100W max

NHIC-9260AT = ICAT Sloped New Construction / 75W max

NHIC-9260AT = ICAT Sloped Remodel / 75W max

Example: **NTS-615C** = 6" Specular Clear Reflector with White Flange