


Part Number: BR-1.5-1/4-20S

Product Description: BRIDLE RING WITH SADDLE - 1 1/2" CAPACITY - MOUNTS WITH 1/4-20 THREADS

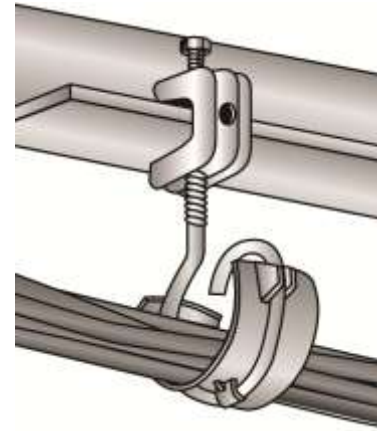

Material Specifications

Type: Assembly
Color: Various

Finish: Assembly

Function Specifications

Compatible Wires and Cables

AC/MC CABLE (OD):
Drop Wire:
Plain Rod (in):

Threaded Rods and Bolts

Tapped Holes:
Clearance Holes (in):
Threaded Rod Size (in): 1/4"-20

Compatible Conduit

EMT Size (in):
Rigid/IMC (in):

Compatible Flanges and Studs

Flange Size (in):
Metal Stud Size (ins):

Static Load Rating

Vertical (lbs):
Horizontal (lbs):

Other

1-1/2 bridle ring with saddle

Codes and Regulatory

Regulatory Certifications: UL/CUL

Country of Origin: US

Packaging

General Packaging: Cardboard Box
Box Size: 8.25 X 6.25 X 6

Pieces per Package: 50
Other Box Features:

Document Information

Created By: DBLA
Checked By: DJW
Approved By: KLN

Customer Specification #: C11444
Revision Level: 0
ECN #: GAECN01813
Date: 3/19/2014