


Part Number: BR-4.0-1/4-20S

Product Description: BRIDLE RING WITH SADDLE - 4" CAPACITY - MOUNTS WITH 1/4-20 THREADS

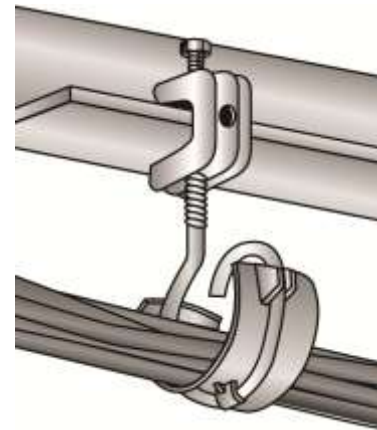

### Material Specifications

Type: Assembly

Color: Various

Finish: Assembly

### Function Specifications

#### Compatible Wires and Cables

AC/MC CABLE (OD):  
Drop Wire:  
Plain Rod (in):

#### Threaded Rods and Bolts

Tapped Holes:  
Clearance Holes (in):  
Threaded Rod Size (in): 1/4"-20

#### Compatible Conduit

EMT Size (in):  
Rigid/IMC (in):

#### Compatible Flanges and Studs

Flange Size (in):  
Metal Stud Size (ins):

#### Static Load Rating

Vertical (lbs):  
Horizontal (lbs):

#### Other

4" bridle ring with saddle

### Codes and Regulatory

Regulatory Certifications: UL/CUL

Country of Origin: US

### Packaging

General Packaging: Cardboard Box  
Box Size: 17 X 13.25 X 10

Pieces per Package: 50  
Other Box Features:

### Document Information

Created By: DBLA  
Checked By: DJW  
Approved By: KLN

Customer Specification #: C11446  
Revision Level: 0  
ECN #: GAECN01813  
Date: 3/19/2014