


## Model# 80047-ULE60-AD3

### Two Handle Wallmount Pre-Rinse Faucet

#### FEATURES & SPECIFICATIONS

- 2-3/8" Lever Handle
- 24" Quick Install Riser With Spring Guide
- 44" Flexible Stainless Steel Hose
- Ceramic Disc Cartridges
- Back Flow Preventers
- 1/2-14 NPS Female Thread 1.1 GPM Flow Rate, 6.5 ozf Spray Force Spray Valve
- 1.1 GPM Flow Rate, 6.5 ozf Spray Force Spray Valve
- 2-Hole 7-7/8" to 8-1/8" Installation
- Pipe Strap and Hook Assembly
- Secondary Control Valve
- Add-On Faucet
- 12" Swivel Tube Spout

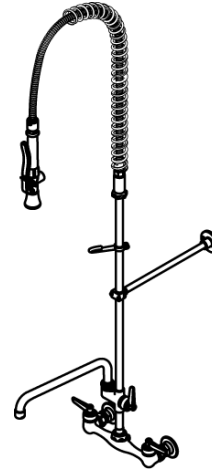

#### FINISHES

- PC Polished Chrome

#### STANDARDS

- ASME A112.18.1
- ANSI / NSF 61, SECTION 9
- CUPC / IAPMO LISTED
- ANSI A117.1 / ADA COMPLIANT
- CONTAINS NO MORE THAN 0.25% WEIGHTED AVERAGE LEAD CONTENT



#### FLOW

- 1.1 GPM Flow Rate, 6.5 ozf Spray Force Spray Valve

#### WARRANTY

- Lifetime Limited Warranty
- Lifetime Residential Warranty
- 5 Year Commercial Warranty


Job Name \_\_\_\_\_ Date \_\_\_\_\_  
Model Specified \_\_\_\_\_ QTY \_\_\_\_\_  
Customer/Wholesaler \_\_\_\_\_  
Contractor \_\_\_\_\_  
Architect/Engineer \_\_\_\_\_  
Submitted as Shown \_\_\_\_\_  
Submitted w/ Variations \_\_\_\_\_

80047-ULE60-AD3/REV. 11 2016

Product Specifications subject to change without notice

## Model# 80047-ULE60-AD3

### Two Handle Wallmount Pre-Rinse Faucet

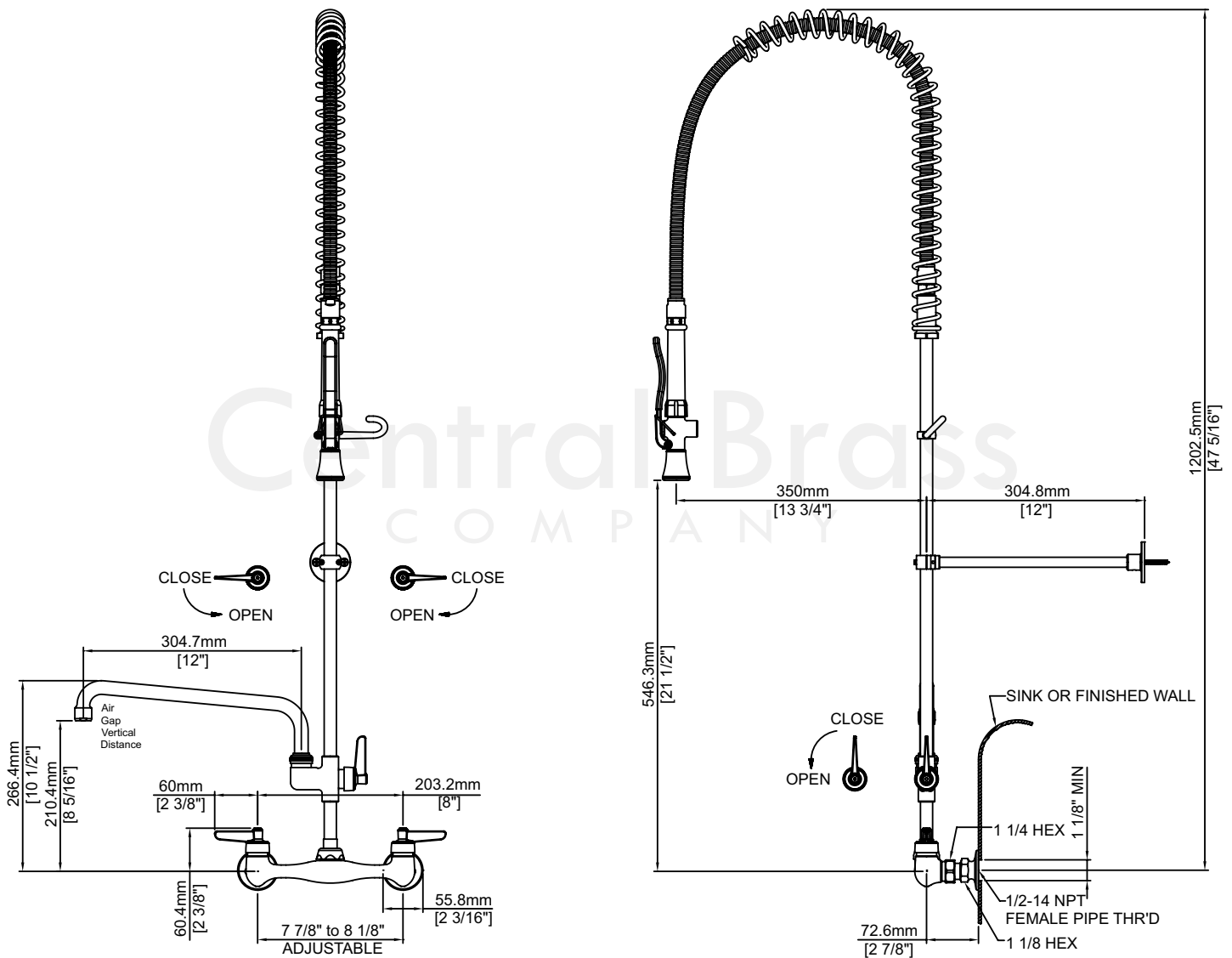

80047-ULE60-AD3/REV. 11 2016

Product Specifications subject to change without notice