


SUNFIRE®

HEATS UP TO 2,800 SQ. FT.


SF120 RADIANT HEATER 120,000 BTUs

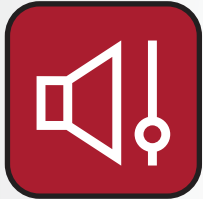

LOW NOISE



ODORLESS

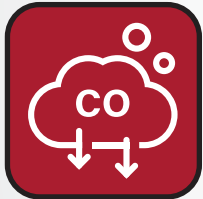

ZERO CO
EMISSIONS*



DUST FREE
EXPERIENCE



XTREME CLEAN™
ADVANCED TECHNOLOGY BURNER

DUAL FUEL
DIESEL/#2  KEROSENE

* Requires 120V of electricity.



THERMOSTAT CONTROL OPTION
CONNECT TO STANDARD WALL THERMOSTAT
(THERMOSTAT NOT INCLUDED)

**MADE IN
USA**

* Zero CO with properly tuned burner and at steady state temperature.

THE ULTIMATE HEATING EXPERIENCE



Advanced technology extends nozzle life and improves burn efficiency to achieve zero* carbon monoxide emissions for superior indoor performance and safety.

*Zero CO with properly tuned burner and at steady state temperature.



Hatch under burner cover offers quick access to the nozzle assembly making tune-ups and maintenance ultra-fast and easy.



Available Accessory: Fuel-Filter Heating Band. Improves startup in extreme cold conditions.

Requires proper ventilation indoors. Not for household residential use.

SPECIFICATIONS

| | | | | |
|--------------------------|--------------------------------------|--|------------------------------------|---|
| BTU/Hr: | 120,000 | Weight: | 120 lbs. Fully Fueled: 218 lbs. | Thermostat Options: Use any mechanical or battery operated wall thermostat. Do not use a thermostat that requires 120V of power. <i>Thermostat not included.</i> |
| Fuel: | Diesel, #2 Fuel Oil, Kerosene | Product Dimensions: | 32"L x 28.5"W x 33.75"H | |
| Flow Rate GPH: | .87 Diesel and .78 Kerosene | Run Time: | 16 Hrs. Diesel / 18 Hrs. Kerosene | |
| Tank Capacity: | 14 Gallons | Minimum Clearances: | Front: 84" Sides: 36" Back: N/A | |
| Electrical Requirements: | 120V 1.2A 60HZ (800W+ Pure Sine INV) | <i>Keep away from combustible items.</i> | | |

SUNFIRE



SunFireHeaters.com