

3-4046-A

Wall Mount, Outdoor, Wet Location

Features

Housing

Die-cast Aluminum with Powder Coated Finish
Finish Options: -05 Black, -30 Oil Rubbed Bronze
Good for Wet Location Applications

Electrical

120V – 277V, Built-in Photo Cell Option
High Power Factor, Low THD

Lamp


Integrate LED Module: Color Temperature Option 3000K, 3500K, 4000K, 5000K

Certification

ETL/cETL Listed

Warranty

5 Years Limited Warranty on Driver and LED

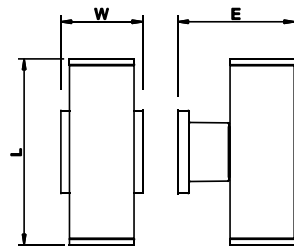

LED Type

Model	Input Voltage	Input Wattage	LED CT/CRI	Lumen (TYP)	Finish	Dimension (L x W X E)	Energy Star
3-4046D-A-05-xxxxK	120V ~ 277V	18W	3000K / >80	1500	Black	10.25" x 4.5" x 6.5"	Yes