

3-4078D

Wall Mount, Outdoor

Features

Housing

Die-cast Aluminum with Powder Coated Finish
Finish Options: -05 Black, -30 Oil Rubbed Bronze, -08 Gray
Good for Wet Location Applications

Optical

Shade: Frosted Glass

Electrical

120V – 277V
High Power Factor, Low THD

Lamp


Integrated LED Module, Color Temperature Option 3000K or 4000K

Certification

ETL/cETL Listed, Suitable for Wet Locations

Warranty

5 Years Limited Warranty on Driver and LED

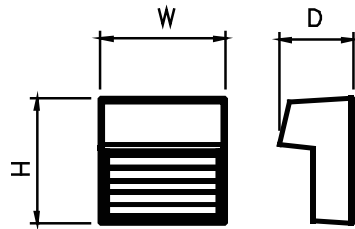

LED Type

Model	Input Voltage	Input Wattage	LED CT	Lumen (TYP)	Finish	Shade	Dimension (W x H x D)
3-4078D-05-xxxxK	120V-277V	9W	3000K or 4000K	350	Black	Frosted Glass	6.3" x 6.3" x 3.8"