

3-5046D

Wall Mount, Up/Down Light, Outdoor, Wet Location

Features

Housing

Die-cast Aluminum with Powder Coated Finish
Finish Options: -05 Black, -30 Oil Rubbed Bronze, -08 Gray
Good for Wet Location Applications

Optical

Shade: Clear Glass

Electrical

120V – 277V
High Power Factor, Low THD

Lamp


Integrate LED Module: Color Temperature Option 3000K or 4000K
LED: High Efficiency, High CRI, Binned and Mixed to Reach Uniform Light

Certification

ETL/cETL Listed, Suitable for Wet Locations

Warranty

5 Years Limited Warranty on Driver and LED

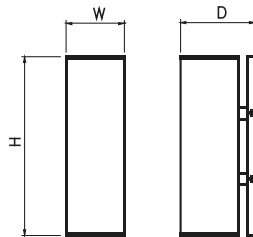

LED Type

Model	Input Voltage	Input Wattage	LED CT	Lumen (TYP)	Finish	Shade	Dimension (H x W X D)	Energy Star
3-5046D-xxxxK-05	120V ~ 277V	34W	3000K or 4000K	3200	Black	Clear Glass	18.1" x 6.0" x 8.2"	---