

# 3-5048D

## Wall Mount, Down Light, Outdoor, Wet Location

### Features

#### Housing

Die-cast Aluminum with Powder Coated Finish  
Finish Options: -05 Black, -30 Oil Rubbed Bronze, -08 Gray  
Good for Wet Location Applications

#### Optical

Shade: Clear Glass

#### Electrical

120V – 277V  
High Power Factor, Low THD

#### Lamp


Integrate LED Module: Color Temperature Option 3000K or 4000K  
LED: High Efficiency, High CRI, Binned and Mixed to Reach Uniform Light

#### Certification

ETL/cETL Listed, Suitable for Wet Locations

#### Warranty

5 Years Limited Warranty on Driver and LED

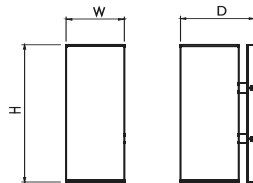

### LED Type

Model	Input Voltage	Input Wattage	LED CT	Lumen (TYP)	Finish	Shade	Dimension (H x W X D)	Energy Star
3-5048D-05-xxxxK	120V ~ 277V	17W	3000K or 4000K	1600	Black	Clear Glass	9.0" x 6.0" x 8.2"	---