

# 3-7001D-A

## Wall Mount, Outdoor

### Features

#### Housing

Die-formed Cold-rolled Steel and Aluminum with Powder Coated Finish  
Finish Options: -05 Black, -08 Gray, -30 Oil Rubbed Bronze  
Good for Wet Location Applications

#### Electrical

120V

#### Lamp


E26 LED Bulb, Color Temperature 3000K or 4000K

#### Certification

ETL/cETL Listed, Suitable for Wet Locations

#### Warranty

5 Years Limited Warranty on Driver and LED

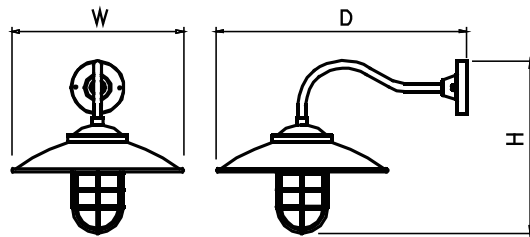

### LED Type

Model	Input Voltage	Input Wattage	LED Lamp	Lumen (TYP)	Finish	Shade	Dimension (W x H x D)
3-7001D-A-05-E26	120V	8W	3000K, A19	800	Black	Glass	13.6" x 13.8" x 20.1"