

3-7005D

Wall Mount, Outdoor

Features

Housing

Die-formed Cold-rolled Steel with Powder Coated Finish
Finish Options: -05 Black, -08 Gray, -30 Oil Rubbed Bronze, -06 White
Good for Wet Location Applications

Electrical


120V

Lamp

E26 LED Bulb, Color Temperature 3000K or 4000K

Certification

ETL/cETL Listed, Suitable for Wet Locations

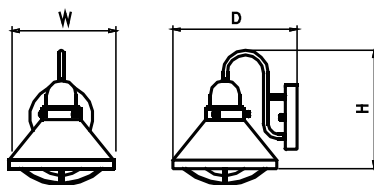

LED Type

Model - Order Code	Input Voltage	Input Wattage	LED Lamp	Lumen (TYP)	Finish	Shade	Dimension (W x H x D)
3-7005D-05-E26	120V	9W	3000K or 4000K, A19	800	Black	Seeded Glass	8.0" x 10.7" x 10.0"