

# FL5524D-E-MCT FL5539D-E-MCT FL5554D-E-MCT

## LED Vanity

### Features

#### Housing

Die-formed Cold-rolled Steel

Finish Option: -30 Oil Rubbed Bronze, - 62 Satin Nickel, -05 Black, -06 White, -09 Silver

#### Optical

Shade: High Transmission Acrylic Create Excellent Light Distribution and Uniformity

LED: High Efficiency, High CRI, Binned and Mixed to Reach Uniform Light.

#### Electrical

High Power Factor, Low THD

#### Lamp


LED Module: Multiple Color Temperature Type (MCT, Adjustable, 3000K/3500K/4000K)

#### Certification

ETL/cETL Listed, Damp Rated

#### Warranty

5 Years Warranty on Driver and LED Module

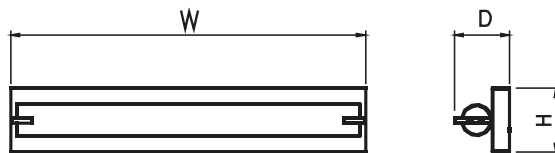

### LED Type

Model	Input Voltage	Input Wattage	LED CT	CRI	Lumen (TYP)	Finish	Shade	Dimension (L X H X E)
FL5524D-E-MCT-62	120V – 277V	17W	3000K/3500K/4000K	>80	1520	Satin Nickel	Acrylic	25.5" x 4.4" x 3.8"
FL5539D-E-MCT-62	120V – 277V	24W	3000K/3500K/4000K	>80	2110	Satin Nickel	Acrylic	37.3" x 4.4" x 3.8"
FL5554D-E-MCT-62	120V – 277V	36W	3000K/3500K/4000K	>80	3220	Satin Nickel	Acrylic	49.1" x 4.4" x 3.8"