


Project Name:	Notes:	Date:	Type:
---------------	--------	-------	-------

Portor's 2-hour fire-rated recessed downlight is an exceptional lighting solution designed to prioritize safety without compromising on aesthetics or functionality. This innovative fixture is engineered to withstand the rigors of a fire for up to two hours, making it an essential choice for commercial and residential applications where fire protection is paramount.

Ideal for soffits, drop ceilings, closets, attics, hallways, bathrooms, kitchens, basements, entry ways, porches (covered ceiling only), garages, stairwells, corridors, nursing/retirement homes, condos, elevators, apartments, and any other small areas with limited space.

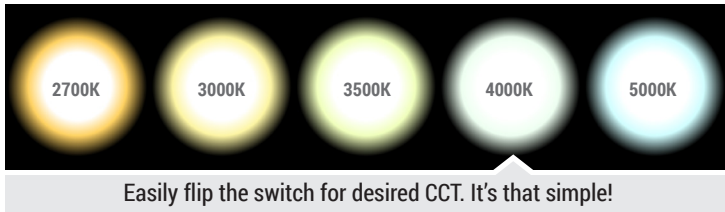

**FEATURES**

- 2-Hour fire rating providing a reinforced and heat resistant steel casing
- LED technology fits anywhere you need general light source
- IC rated for direct contact with insulation
- Perfect solution where joists or duct work would normally prevent recessed installation
- Wet location rated for soffit applications
- Easy installation, no housing required

**DIMMING**

Triac dimmable down to 100%-10%.  
Compatible with most major brands of dimmers.

**LISTING**

ETL Listed, Wet location, Energy Star Listed

WATTAGE	DELIVERED LUMENS	EFFICACY
12W	792 @ 2700K	up to 72 lm/W
	826 @ 3000K	
	869 @ 3500K	
	875 @ 4000K	
	840 @ 5000K	


**TECHNICAL SPECIFICATION**

WATTAGE	12W
VOLTAGE	120V, 60 Hz
CCT	27K/30K/35K/40K/50K
CRI	90
BEAM ANGLE	120°
RATING	Suitable for wet locations
DIMMABLE	Triac dimming
POWER FACTOR	>0.9
OPERATING TEMP	-4°F~104°F (20~40°C)
WARRANTY	5 year limited



MODEL NUMBER(S)						
MODEL#	WATTS	LUMENS	LM/WATT	CCT	CRI	VOLTAGE
PT-DLS-R-FR-4I-12W-5CCT	12W	875 (at 4000K)	72	2700K/3000K/3500K/ 4000K/5000K	90	120V

Project Name:	Notes:	Date:	Type:
---------------	--------	-------	-------

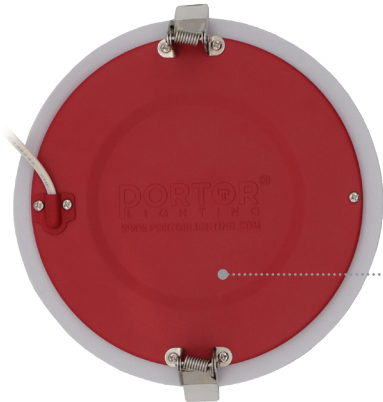

• Sealing gasket standard



**PROVIDING A REINFORCED AND HEAT RESISTANT STEEL CASING**


Tested to comply with UL 263, ASTM E119 & CAN ULC S101



2700K | 3000K | 3500K | 4000K | 5000K

Change color temperature with the simple flip of a switch

**DIMENSION**

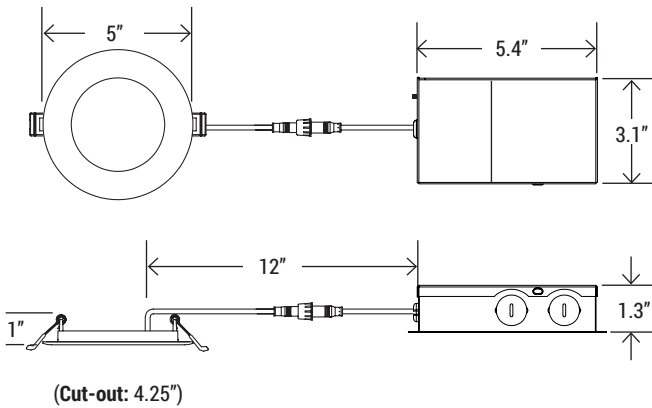

**MOUNTING OPTIONS**



**UNI-DLS**  
4"/6" Universal Slim LED Housing for New Construction



**RP-DLS-4I**  
4" Slim LED Rough plate

**COMPATIBLE DIMMERS**

LUTRON*	LEVITON*	LEGRAND
<ul style="list-style-type: none"> <li>• CT-600P</li> <li>• DVLC-153P</li> <li>• MSCL-OP153M</li> <li>• PD-6WCL</li> <li>• MACL-153M/MA-R</li> <li>• TG-600PR-WH</li> <li>• S-600PR-WH</li> <li>• CTCL-153PDH-WH</li> <li>• TGCL-153PH-LA</li> <li>• SLV-600P-AL</li> <li>• DV-600PR-WH</li> <li>• SCL-153PH-WH</li> </ul>	<ul style="list-style-type: none"> <li>• RNL06</li> <li>• 6672</li> <li>• 6674</li> <li>• IPL06</li> <li>• DLS06</li> <li>• SELV-300P-WH</li> <li>• VP106-1LZ</li> </ul>	<ul style="list-style-type: none"> <li>• ADTP70TU</li> </ul>

\*For more details, please visit company's website