


Catalog Number:	Project Name:	Note:	Date:	Type:
-----------------	---------------	-------	-------	-------

Portor's PT-WPH3 series combines economical and security solution for outdoor perimeter and building facades. WPH3 is wattage and color selectable, and can be programmed with a CCT of 4000K, 4500K or 5000K, eliminating the need to stock multiple color temperatures.

Ideal use for warehouses, walkways, building entry ways, parking lots, retail exteriors and shopping malls.

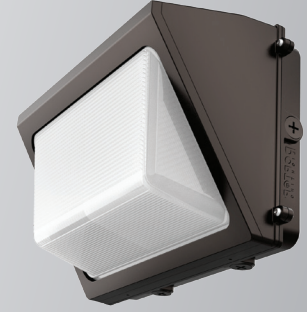

CCT
SELECTABLE

WATTAGE
SELECTOR

CONSTRUCTION

Die-Cast aluminum housing. Sealed by a silicone ring that makes the fixture waterproof, internal level ensures installation is horizontal.

ELECTRICAL

Luminaire is built with the highest quality driver that is Universal Voltage (120V-277V), uses long lasting, high-efficient LED packages.

OPTICAL SYSTEM

Borosilicate glass lens designed to reduce glare and improve over-all light distribution through precision formed LED optics.

ENERGY SAVINGS

Over 50% energy savings than traditionally fluorescent fixtures, low heat productions requires less maintenance and operation cost.

LISTING

UL Listed, DLC Premium Listed

WARRANTY

5 year Limited Warranty, Rated for 50,000 hours. See Warranty documentation for details.

PART #	WATTAGE	DELIVERED LUMENS	EFFICACY
PT-WPH3-LW	45W	6176	134 lm/W
	60W	8256	131 lm/W
	75W	9466	127 lm/W
PT-WPH3-HW	80W	9083	128 lm/W
	100W	11638	126 lm/W
	120W	13741	120 lm/W

Based on actual wattage setting @ 4000K. Actual lumens may vary.

TECHNICAL SPECIFICATION

CCT	4000K/4500K/5000K
CRI	82
DIMMABLE	0-10V Dimming
VOLTAGE	120V-277V
POWER FREQUENCY	50/60 Hz
POWER FACTOR	>0.9
THD	≤20%
WORKING TEMPERATURE	-40°F ~ 113°F
IP RATING	IP65 Wet Location
WARRANTY	5 year limited




ORDERING SAMPLE:

- - - -

Series	Wattage	CCT	Accessories/Options		
PT-WPH3 Commercial Grade Wall Pack Luminaire	LW (45W/60W/75W)	3CP (4000K/4500K/5000K)	Photocell	Motion Sensor	EM Battery
	HW (80W/100W/120W)		blank P (Photocell)	blank MS-WP3 MSS-RC-100	blank EM (EM battery)

Catalog Number:	Project Name:	Note:	Date:	Type:
-----------------	---------------	-------	-------	-------

DIMENSION

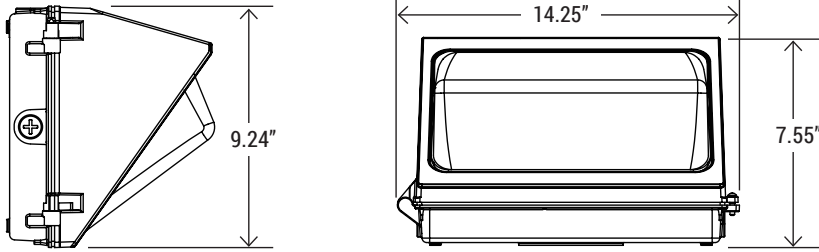

PHOTOCELL OPTION



PSA
Adjustable Photocell



PSB
Photocell

MOTION SENSOR OPTION



MS-WP3
Microwave Motion
Sensor (100V-277V)



MSS-RC-100
Remote Control

EM BATTERY



EM
LED Emergency Driver



DLC LISTING

CATALOG NUMBER	WATTAGE	DELIVERED LUMENS	EFFICACY	DLC PRODUCT ID	CLASSIFICATION
PT-WPH3-LW-3CP	75W	9,466 @ 4000K	135 lm/W	S-9VT70A	PREMIUM
PT-WPH3-HW-3CP	120W	13,741 @ 4000K	135 lm/W	S-PUQ9GV	PREMIUM

Based on actual wattage setting @ 4000K. Actual lumens may vary.