




## USKC24-12-12-SS

Ruland USKC24-12-12-SS, 3/4" x 3/4" Single Universal Joint, Needle Bearing, Stainless Steel, Set Screw With Keyway, 1.495" OD, 4.250" Length

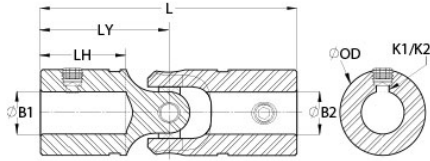

### Description

Ruland USKC24-12-12-SS is a single cardan needle bearing universal joint with 0.7500" x 0.7500" bores, 3/16" x 3/16" keyways, 1.495" OD, 4.250" length, and 5/16-18 x 1/4 set screws. It is ideal for applications where higher accuracy, service life, and speed are required. This needle bearing universal joint is comprised of needle roller bearings, precision machined trunnions with hardened and ground journals, and two yokes for reduced friction and increased performance in high performance applications. USKC24-12-12-SS is designed for use in high RPM applications up to 6000 RPM and has extended service life due to pre-lubricated maintenance free bearings. It is made from high grade stainless steel for increased corrosion resistance. When combined with bootUBOOT24/38-NI-KIT the joint is protected from unwanted contaminants such as dust or water and self lubricates reducing maintenance time. This single cardan universal joint is manufactured in the USA by Belden Universal for strict control of processes.

### Product Specifications

<b>Bore (B1)</b>	0.7500 in	<b>Small Bore (B2)</b>	0.7500 in
<b>Keyway (K1)</b>	3/16 in	<b>Keyway (K2)</b>	3/16 in
<b>B1 Max Shaft Penetration</b>	1.380 in	<b>B2 Max Shaft Penetration</b>	1.380 in
<b>Joint Outer Diameter (OD)</b>	1.495 in	<b>Bore Tolerance</b>	+0.0010 in / -0.0000 in
<b>Length (L)</b>	4.250 in	<b>Yoke Length (LY)</b>	2.125 in
<b>Hub Depth (LH)</b>	1.380 in	<b>Broached Set Screw</b>	5/16-18
<b>Screw Material</b>	Stainless Steel	<b>Max Operating Angle</b>	45°
<b>Material Specification</b>	Yokes: 303 Stainless Steel Pins and Blocks: 416 Stainless Steel	<b>Manufacturer</b>	Belden Universal
<b>Country of Origin</b>	USA	<b>Weight (lbs)</b>	1.355000
<b>Recommended Lubricant</b>	LUBRIPLATE No. 1200-2	<b>Matching Boot Cover</b>	<a href="#">UBOOT24/38-NI-KIT</a>
<b>UPC</b>	634529290415	<b>Tariff Code</b>	8483.60.4000
<b>UNSPC</b>	25173810		
<b>Note 1</b>	Performance ratings are for guidance only. The user must determine suitability for a particular application.		
<b>Prop 65</b>	⚠️ WARNING This product can expose you to the chemical Nickel (metallic), known to the State of California to cause cancer. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a> .		