

A23

# LF3-HL-D-KN

## 0-10V DIMMING



LF3-HL-30W-D-KN



LF3-HL-50W-D-KN

### TECHNICAL SPECIFICATIONS:


- :: Housing: Die-cast aluminum housing with powder coat finish (Dark Bronze or White)
- :: Philips Lumileds Lexeon 3030 high flux LED
- :: optic lens - TYPE II
- :: Cord type: 13" #18 AWG stranded wires
- :: Voltage: 120-277V; 60Hz AC
- :: 0~10V dimming
- :: Operating Temp: -4°F to 104°F
- :: Up to 110 lumens per watt
- :: CRI: 82~84
- :: Beam Angle: 120°X90°
- :: 70,000 hour rated life
- :: 7-year warranty
- :: Suitable for Wet Locations, IP65
- :: Solid state lighting technology for long life, no maintenance needed and high-efficiency

### APPLICATIONS:

- :: Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas.
- :: Replace existing HID flood lights/ wall packs
- :: Great for use with motion sensors or other bi-level controls



**OPTIONS**  
FIXTURE COLOR

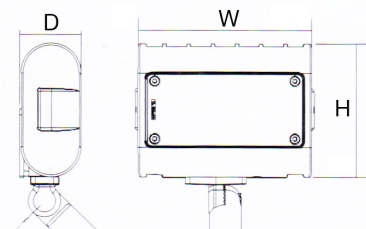

## LF3 0-10 DIMMING FLOOD LIGHT SERIES WITH 1/2" KNUCKLE

CATALOG NO.	WATTS	LUMENS	COLOR TEMP	REPLACEMENT RANGE	DIMENSIONS
LF3-HL-30W-50K-D-KN	30W	3600LM	5000K	70~100 MH	6-3/4"(W) x 5-1/8"(H) x 1-3/5"(D) x 3-2/3"(K)
LF3-HL-30W-40K-D-KN	30W	3600LM	4000K	70~100 MH	
LF3-HL-30W-30K-D-KN	30W	3600LM	3000K	70~100 MH	
LF3-HL-50W-50K-D-KN	50W	6100LM	5000K	100~175 MH	8-1/2"(W) x 6"(H) x 1-4/5"(D) x 3-2/3"(K)
LF3-HL-50W-40K-D-KN	50W	6100LM	4000K	100~175 MH	
LF3-HL-50W-30K-D-KN	50W	6100LM	3000K	100~175 MH	