

LF4-SF



LF4-80W-SF
LF4-100W-SF



LF4-150W-SF




BACK VIEW

TECHNICAL SPECIFICATIONS:

- :: Housing: Die-cast aluminum housing with powder coat finish (Dark Bronze)
- :: Voltage: 120~277V; 60Hz AC
- :: 0~10V dimming
- :: TIR optic lens - TYPE II
- :: 13" #18 AWG stranded wires
- :: Power Factor: .9~.97
- :: Operating Temp: -4°F to 104°F
- :: Up to 110 lumens per watt
- :: CRI: 82~84
- :: 70,000 hour rated life
- :: Suitable for Wet Locations, IP65

APPLICATIONS:

- :: Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas.
- :: Great for use with motion sensors or other instant on/off controls

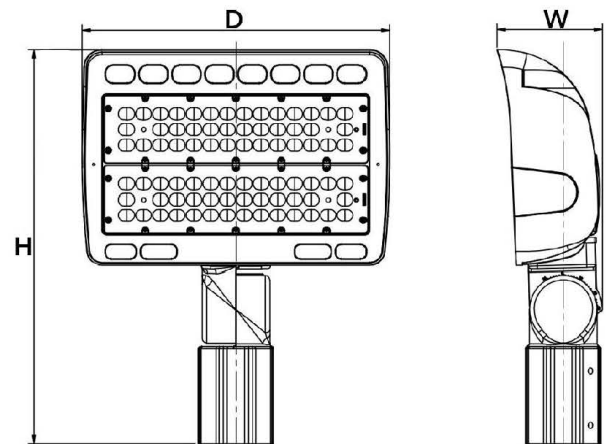

LF4 ARCHITECTURAL SERIES WITH SLIP FITTER (120V-277V)

| CATALOG NO. | WATTS | LUMENS | COLOR TEMP | REPLACEMENT RANGE | DIMENSIONS |
|--------------|-------|---------|------------|-------------------|-------------------------------|
| LF4-80CW-SF | 80W | 9500LM | 5000K | 150~250 MH | 11.8"(H) x 10.9"(W) x 8.4"(D) |
| LF4-80WW-SF | 80W | 9500LM | 3000K | 150~250 MH | |
| LF4-100CW-SF | 100W | 11200LM | 5000K | 200~400 MH | |
| LF4-100WW-SF | 100W | 11200LM | 3000K | 200~400 MH | |
| LF4-150CW-SF | 150W | 17000LM | 5000K | 320~400 MH | 17"(H) x 13.3"(W) x 9.3"(D) |
| LF4-150WW-SF | 150W | 17000LM | 3000K | 320~400 MH | |

