

LF4-TR



LF4-80W-TR
LF4-100W-TR



LF4-12W-TR



LF4-30W-TR



LF4-150W-TR




LF4-50W-TR

TECHNICAL SPECIFICATIONS:

- :: Housing: Die-cast aluminum housing with powder coat finish (Dark Bronze)
- :: Voltage: 347~480V
- :: 0~10V dimming (except 80W)
- :: TIR optic lens - TYPE II
- :: 18" SJTW 18/3 AWG cable
- :: Power Factor: .9~.97
- :: Operating Temp:-4°F to 104°F
- :: Up to 110 lumens per watt
- :: CRI: 82~84
- :: 70,000 hour rated life
- :: Suitable for Wet Locations, IP65

APPLICATIONS:

- :: Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas.
- :: Great for use with motion sensors or other instant on/off controls

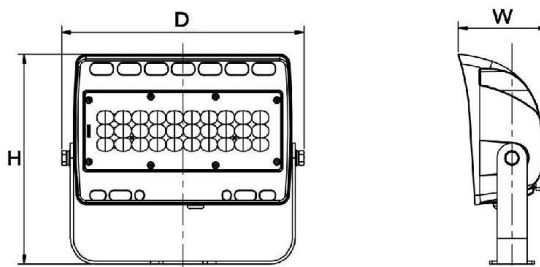

LF4 ARCHITECTURAL SERIES WITH TRUNNION(120V-277V)

CATALOG NO.	WATTS	LUMENS	COLOR TEMP	REPLACEMENT RANGE	DIMENSIONS
LF4-12CW-TR	12W	1300LM	5000K	50~70 MH	4.9"(H) x 4.7"(W) x 2.5"(D)
LF4-12WW-TR	12W	1200LM	3000K	50~70 MH	
LF4-30CW-TR	30W	3300LM	5000K	70~100 MH	7.2"(H) x 6.8"(W) x 3.07"(D)
LF4-30WW-TR	30W	3100LM	5000K	70~100 MH	
LF4-50CW-TR	50W	5600LM	3000K	100~175 MH	8.2"(H) x 8.6"(W) x 3.54"(D)
LF4-50WW-TR	50W	5400LM	5000K	100~175 MH	
LF4-80CW-TR	80W	9500LM	3000K	100~175 MH	16.4"(H) x 10.9"(W) x 8.4"(D)
LF4-80WW-TR	80W	9500LM	5000K	100~175 MH	
LF4-100CW-TR	100W	11200LM	3000K	150~250 MH	
LF4-100WW-TR	100W	11200LM	5000K	150~250 MH	
LF4-150CW-TR	150W	17000LM	3000K	200~400 MH	12.4"(H) x 13.3"(W) x 9.3"(D)
LF4-150WW-TR	150W	17000LM	5000K	200~400 MH	

