


# LWA



12W, 20W, 30W, 50W  
Available in white

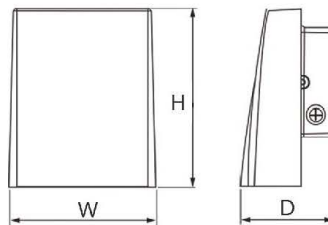

## TECHNICAL SPECIFICATIONS:

- :: Full cutoff, dark sky compliant
- :: Die-cast aluminum with powder coat finish (Dark Bronze or White)
- :: Philips Lumileds Lexeon 3030 high flux LED
- :: TIR optic lens - TYPE II (TYPE III by special order)
- :: 120~277V
- :: CRI: >80
- :: Power Factor: 95%
- :: Operating Temp:-4°F to 104°F
- :: 70,000 hour rated life
- :: 7-year warranty
- :: Suitable for Wet Locations, IP54

## APPLICATIONS:

- :: Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas.
- :: Replace existing HID flood lights/ wall packs
- :: Great for use with motion sensors or other instant on/off controls



## LED CUTOFF & ADJUSTABLE WALL PACK

CATALOG NO.		WATTS	LUMENS	COLOR TEMP	REPLACEMENT RANGE	DIMENSIONS
BRONZE	WHITE					
LWA-12-WW	LWA-12-WW-WH	12W	1100LM	3000K	50~70 MH	6-1/2" (w) x 8" (H) x 4" (D)
LWA-12-CW	LWA-12-CW-WH	12W	1200LM	5000K	50~70 MH	
LWA-20-WW	LWA-20-WW-WH	20W	2000LM	3000K	70~100 MH	9" (w) x 12" (H) x 6" (D)
LWA-20-CW	LWA-20-CW-WH	20W	2200LM	5000K	70~100 MH	
LWA-30-WW	LWA-30-WW-WH	30W	3000LM	3000K	100~125 MH	
LWA-30-CW	LWA-30-CW-WH	30W	3200LM	5000K	100~125 MH	
LWA-50-WW	LWA-50-WW-WH	50W	4900LM	3000K	150~200 MH	11" (w) x 13" (H) x 6.5" (D)
LWA-50-CW	LWA-50-CW-WH	50W	5200LM	5000K	150~200 MH	
LWA-80-WW	-	80W	8800LM	3000K	200~300 MH	
LWA-80-CW	-	80W	9000LM	5000K	200~300 MH	
LWA-120-WW	-	120W	13700LM	3000K	300~400 MH	
LWA-120-CW	-	120W	13700LM	5000K	300~400 MH	

LWA-KNU



1/2" knuckle adaptor with back plate and screws, for 20W and 30W only

