
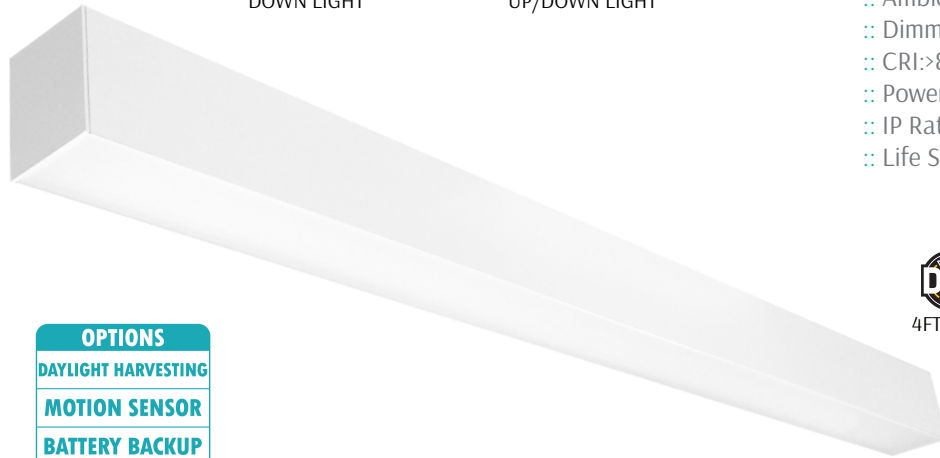


SCX

B13

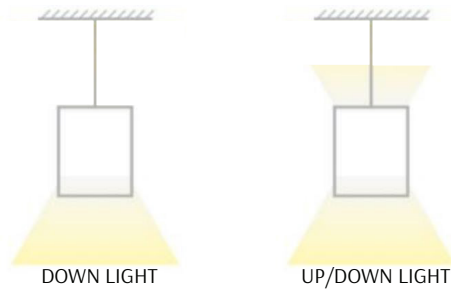

- OPTIONS**
- DAYLIGHT HARVESTING
 - MOTION SENSOR
 - BATTERY BACKUP
 - FIXTURE COLOR

TECHNICAL SPECIFICATIONS:

- :: Seamless Linkable Linear Lighting System
- :: Opal Polycarbonate Lens
- :: Housing: White, Aluminum
- :: Matte White Finish
- :: Optional Recessed & Wall Mounting Kits available
- :: Voltage: 120-277VAC 50/60Hz
- :: Ambient Temperature: -13°F~104°F
- :: Dimmable: 0~10V dimmable
- :: CRI:>80
- :: Power Factor:>0.95
- :: IP Rating: IP54
- :: Life Span: 50,000 hours, 5-year warranty




LED SUPERIOR ARCHITECTURAL LIGHTS

CATALOG NO.	LENGTH	WATTS	LUMENS	COLOR TEMP	DIMENSIONS
SCX-2FT-20W-30K-D	2FT	20W	2240LM	3000K	24"(L) x 2-3/4"(W) x 3-3/8"(H)
SCX-2FT-20W-35K-D	2FT	20W	2300LM	3500K	
SCX-2FT-20W-40K-D	2FT	20W	2360LM	4000K	
SCX-2FT-20W-50K-D	2FT	20W	2420LM	5000K	36"(L) x 2-3/4"(W) x 3-3/8"(H)
SCX-3FT-30W-30K-D	3FT	30W	3360LM	3000K	
SCX-3FT-30W-35K-D	3FT	30W	3450LM	3500K	
SCX-3FT-30W-40K-D	3FT	30W	3540LM	4000K	48"(L) x 2-3/4"(W) x 3-3/8"(H)
SCX-3FT-30W-50K-D	3FT	30W	3630LM	5000K	
SCX-4FT-40W-30K-D	4FT	40W	4480LM	3000K	
SCX-4FT-40W-35K-D	4FT	40W	4600LM	3500K	72"(L) x 2-3/4"(W) x 3-3/8"(H)
SCX-4FT-40W-40K-D	4FT	40W	4720LM	4000K	
SCX-4FT-40W-50K-D	4FT	40W	4840LM	5000K	
SCX-6FT-60W-30K-D	6FT	60W	6720LM	3000K	96"(L) x 2-3/4"(W) x 3-3/8"(H)
SCX-6FT-60W-35K-D	6FT	60W	6900LM	3500K	
SCX-6FT-60W-40K-D	6FT	60W	7080LM	4000K	
SCX-6FT-60W-50K-D	6FT	60W	7260LM	5000K	
SCX-8FT-80W-30K-D	8FT	80W	8960LM	3000K	
SCX-8FT-80W-35K-D	8FT	80W	9200LM	3500K	
SCX-8FT-80W-40K-D	8FT	80W	9440LM	4000K	
SCX-8FT-80W-50K-D	8FT	80W	9680LM	5000K	

SCX



B14

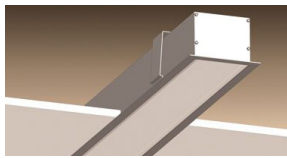

Recessed Mounted (Flanged)



Surface Mounted




Wall Mounted



Suspended




T-Bar Installation

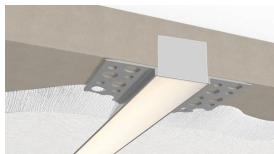


Flangless Recessed Mounted (Mud-In)



Louver Kit Option

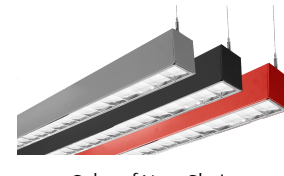

Color of Your Choice

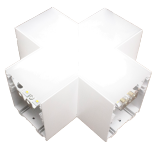


X Module

- SCX-X-30K-D
- SCX-X-35K-D
- SCX-X-40K-D
- SCX-X-50K-D



T Module

- SCX-T-30K-D
- SCX-T-35K-D
- SCX-T-40K-D
- SCX-T-50K-D

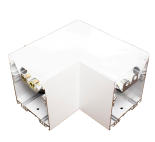

L Module

- SCX-L-30K-D
- SCX-L-35K-D
- SCX-L-40K-D
- SCX-L-50K-D



Inside Corner Module

- SCX-IC-30K-D
- SCX-IC-35K-D
- SCX-IC-40K-D
- SCX-IC-50K-D




120° Corner Module

- SCX-C120-30K
- SCX-C120-35K
- SCX-C120-40K
- SCX-C120-50K



Suspension Rod Kit

- SCL-RS-12 12"
- SCL-RS-18 18"
- SCL-RS-24 24"
- SCL-RS-36 36"
- SCL-RS-48 48"

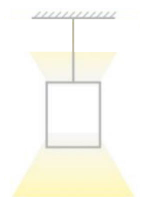

Up Light Option

- 3000K
- 3500K
- 4000K
- 5000K
- Blue
- Green