

ULHB DLC PREMIUM


120-277V

TECHNICAL SPECIFICATIONS:


- :: Housing: Aluminum heat sink, outdoor powder coating.
- :: Voltage: 120-277V AC; 60Hz AC
- :: Cord type: 6' SJTW 18/3 AWG cable
- :: Efficacy: 130LM/W
- :: CRI: >80
- :: Power Factor: ≥0.9
- :: Beam Angle: 110°
- :: THD: <20%
- :: 0~10V Dimming
- :: Operating Temp.: -4°F to 122°F
- :: Aluminum LED Board: High conductive, waterproof, aging resistant, salt mist resistance, long-life
- :: 5-year warranty




150W & 200W
5000K
Available in white

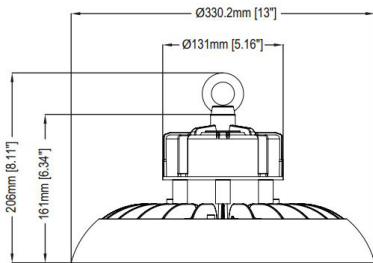

ULHB-100W

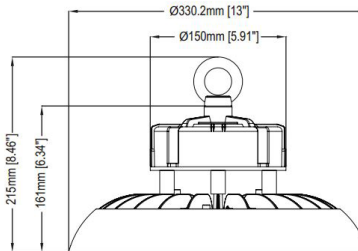

ULHB-150W

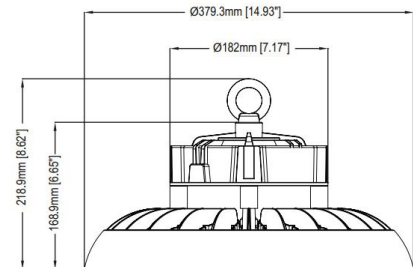

ULHB-200W/240W

LED HIGH-LUMEN UFO HIGH BAY

CATALOG NO.		WATTS	LUMENS	COLOR TEMP	REPLACEMENT RANGE	DIMENSIONS
BRONZE	WHITE					
ULHB-100W-50K	-	100W	13000LM	5000K	150~250 MH	13"(Diameter) x 8.11" (H)
ULHB-100W-40K	-	100W	13000LM	4000K	150~250 MH	
ULHB-100W-30K	-	100W	13000LM	3000K	150~250 MH	
ULHB-150W-50K	ULHB-150W-50K-WH	150W	19500LM	5000K	200~400 MH	13"(Diameter) x 8.46" (H)
ULHB-150W-40K	-	150W	19500LM	4000K	200~400 MH	
ULHB-150W-30K	-	150W	19500LM	3000K	200~400 MH	
ULHB-200W-50K	ULHB-200W-50K-WH	200W	26000LM	5000K	350~400 MH	14.93"(Diameter) x 8.62" (H)
ULHB-200W-40K	-	200W	26000LM	4000K	350~400 MH	
ULHB-200W-30K	-	200W	26000LM	3000K	350~400 MH	
ULHB-240W-50K	-	240W	31200LM	5000K	1000 MH	
ULHB-240W-40K	-	240W	31200LM	4000K	1000 MH	
ULHB-240W-30K	-	240W	31200LM	3000K	1000 MH	

ACCESSORIES FOR UFO HIGH BAYS




ULHB-PCR-100/150
ULHB-PCR-200/240



ULHB-ALR-100/150
ULHB-ALR-200/240



ULHB-90KIT-100/150
ULHB-90KIT-200/240

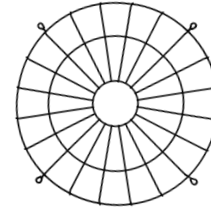

ULHB-WG-100/150
ULHB-WG-200/240



ULHB-SC-100/150
ULHB-SC-200/240




ULHB-PCC-100/150
ULHB-PCC-200/240



ULHB-SMB-100/150
ULHB-SMB-200/240



ULHB-SK
ULHB-SK-480V

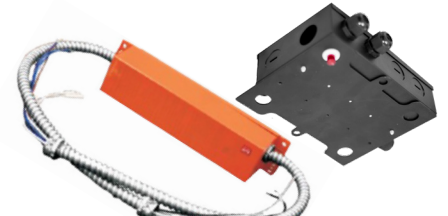

ULHB-EMK

B32

LED HIGH BAYS

ULHB SERIES ACCESSORIES

CATALOG NO.	DESCRIPTION
ULHB-PCR-100/150	Polycarbonate Reflector for 100W & 150W
ULHB-PCR-200/240	Polycarbonate Reflector for 200W & 240W
ULHB-ALR-100/150	Aluminum Reflector for 100W & 150W
ULHB-ALR-200/240	Aluminum Reflector for 200W & 240W
ULHB-90KIT-100/150	90° Degree Reflector and Glass Kit for 100W & 150W (Conversion from default 110° beam angle)
ULHB-90KIT-200/240	90° Degree Reflector and Glass Kit for 200W & 240W (Conversion from default 110° beam angle)
ULHB-WG-100/150	Wire Guard for 100W & 150W
ULHB-WG-200/240	Wire Guard for 200W & 240W
ULHB-SC-100/150	Safety Cable for 100W & 150W
ULHB-SC-200/240	Safety Cable for 200W & 240W
ULHB-PCC-100/150	Polycarbonate Cover for 100W & 150W (for ULHB-PCR-100/150 only) - Increases heat captured in the reflector. Not recommended when not necessary.
ULHB-PCC-200/240	Polycarbonate Cover for 200W & 240W (for ULHB-PCR-200/240 only) - Increases heat captured in the reflector. Not recommended when not necessary.
ULHB-SMB-100/150	Surface Mount Bracket for 100W & 150W
ULHB-SMB-200/240	Surface Mount Bracket for 200W & 240W
ULHB-SK	Ultrasonic Bi-Level (Dimming) Motion Sensor Kit for 120-277V UFO High Bays Includes special junction box (mounts on fixture), auxiliary cable & push-in connectors
ULHB-SK-480V	Ultrasonic Bi-Level (Dimming) Motion Sensor Kit for 480V UFO High Bays
ULHB-EMK	Emergency Battery Backup Kit for 120-277V UFO High Bays (All wattages) Emergency output power: 11W~28W, Emergency operation: ≥90 mins., Recharge: 48 Hrs. Includes special junction box with test button (mounts on fixture), auxiliary cables & splicers & push-in connector