


# WML-HL



Shown with Optional Shroud  
See Page A27

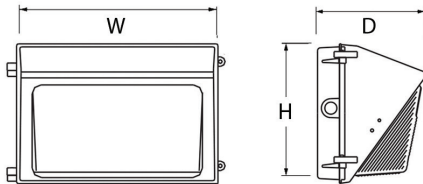

- OPTIONS**
- PHOTOCELL
  - MOTION SENSOR
  - BATTERY BACKUP
  - FIXTURE COLOR

## TECHNICAL SPECIFICATIONS:

- :: Die-cast aluminum with powder coat finish (Dark Bronze), optimized for LED
- :: Same footprint as traditional HID wall packs
- :: Prismatic borosilicate glass lens
- :: Four 1/2" hubs: 1 top, 1 on each side, 1 rear
- :: Chip: Philips Lumileds LEDs
- :: CRI: >80
- :: Power Factor: 95%
- :: Operating Temp: -4°F to 104°F
- :: 70,000 hour rated life
- :: 7-year warranty
- :: Suitable for Wet Locations, IP54

## APPLICATIONS:

- :: Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas.
- :: Replace existing HID wall packs
- :: Great for use with photocell



## LED NON-CUTOFF WALL PACKS

CATALOG NO.	WATTS	LUMENS	COLOR TEMP	REPLACEMENT RANGE	DIMENSIONS
WML-HL-30W-50K	30W	4200LM	5000K	100~150 MH	8-1/2"(W) x 9"(H) x 7-1/4"(D)
WML-HL-30W-40K	30W	4200LM	4000K	100~150 MH	
WML-HL-30W-30K	30W	4200LM	3000K	100~150 MH	
WML-HL-50W-50K	50W	7100LM	5000K	100~200 MH	15-1/4"(W) x 9-1/2"(H) x 7-1/2"(D)
WML-HL-50W-40K	50W	7100LM	4000K	100~200 MH	
WML-HL-50W-30K	50W	7100LM	3000K	100~200 MH	
WML-HL-60W-50K	60W	8700LM	5000K	175~250 MH	
WML-HL-60W-40K	60W	8700LM	4000K	175~250 MH	
WML-HL-60W-30K	60W	8700LM	3000K	175~250 MH	
WML-HL-80W-50K	80W	11600LM	5000K	250~350 MH	18-1/4"(W) x 9"(H) x 9-1/4"(D)
WML-HL-80W-40K	80W	11600LM	4000K	250~350 MH	
WML-HL-80W-30K	80W	11600LM	3000K	250~350 MH	
WML-HL-100W-50K	100W	14800LM	5000K	350~450 MH	
WML-HL-100W-40K	100W	14800LM	4000K	350~450 MH	
WML-HL-100W-30K	100W	14800LM	3000K	350~450 MH	
WML-HL-120W-50K	120W	17100LM	5000K	250~450 MH	18-1/4"(W) x 9"(H) x 9-1/4"(D)
WML-HL-120W-40K	120W	17100LM	4000K	250~450 MH	
WML-HL-120W-30K	120W	17100LM	3000K	250~450 MH	