




DIMENSIONS:

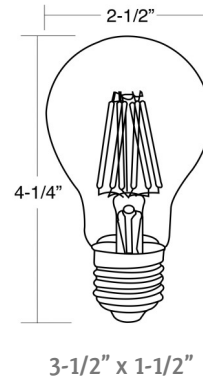

A19-FLA-7W-27K-D
A19-FLA-7W-40K-D

A19-FLA-7W-D

Westgate's dimmable LED lamp technology provides a soft, even illumination without hot spots or LED imaging. Our compact size and excellent thermal management make Westgate LED lamps the choice of professionals.

MODEL NO.	WATTAGE	LUMENS	BEAM	COLOR TEMP
A19-FLA-7W-27K-D	7W	700	360°	WW 2700K
A19-FLA-7W-40K-D	7W	800-850	360°	CW 4000K

ELECTRICAL SPECIFICATIONS:

- Voltage: 120V AC/ 60Hz
- Wattage: 13W
- Power factor: 90% +
- Energy-efficient label (EEL): A++

LIGHTING SPECIFICATIONS:

- Dimmable: Yes 10~100%
- Lumens: 700lm (2700K) 800-850 lm (4000K)
- Color temp: 2700K (Warm white) and 4000K (Natural white)
- CRI: >80
- Beam angle: 360°
- Base: E12 Candelabra
- Lifespan: 30,000 hours

HOUSING SPECIFICATIONS:

- Finish: Clear glass
- Long life—reduced re-lamping cost
- Contains no mercury
- Emits no UV/IR light

WARRANTY:

- Five-year warranty

CERTIFICATIONS:

- UL listed

