


DIMENSIONS:

13.15"(H) x 5.50"(D)

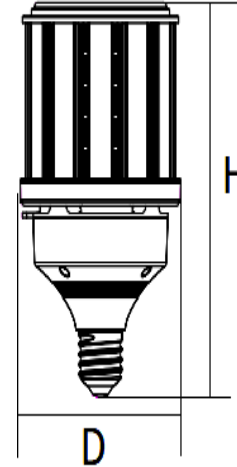

CL-HL-300W-50K-E39

LED CORN LIGHT

Ideal for general site lighting, alleys, loading docks, doorway, pathway, and parking areas.

ELECTRICAL SPECIFICATIONS:

- Voltage: 100~277VAC, 50/60Hz
- Wattage: 300W
- Power factor: 0.90
- Efficacy: 130LM/W

HOUSING SPECIFICATIONS:

- Big heat sink, No fans
- Lamp plastic housing and Sealant pouring for whole driver
- Do not use the lamps in enclosed fixtures
- Operating temperature: -4°F to 149°F
- Suitable for damp location

CERTIFICATIONS: UL,DLC



LIGHTING SPECIFICATIONS:

- 360° degree lighting
- LED type: SMD2835
- Lamp Base: E39
- Lens: optical Lens
- Total lumens: 43500LM
- Color temperature: 5000K
- Color rendering index: >80

WARRANTY: 5 years

MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
CL-HL-300W-50K-E39	300W	100~277VAC	43500LM	5000K

