




CRE-08-30K-BR
CRE-08-40K-BR
CRE-08-50K-BR

CRE-08-30K-SIL
CRE-08-40K-SIL
CRE-08-50K-SIL

DIMENSIONS:

19.75"(L) x 5"(W) x 4.5"(D)

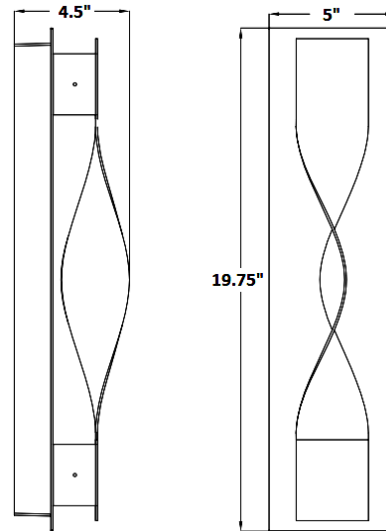

CREST BY WESTGATE LED WALL SCONCES

Ideal for general site lighting, residential houses, doorway.

ELECTRICAL SPECIFICATIONS:

- Voltage: 100~277ACV
- Wattage: 10W(2.5W X 4)
- Power Factor: 0.95
- Efficacy: 90LM/W

HOUSING SPECIFICATIONS:

- Patent-Pending design with separate light engine (base) and interchangeable designer trims expand the series to multiple color temperatures and models.
- Series can be stocked as separate engines and trims to offer a versatile collection at the store level
- Die-cast Aluminum weatherproof housing, steel backplate, Aluminum Trim (Dark Bronze or Silver)
- Operating temperature: -40°F to 107°F
- Lifespan: 50,000 hr.
- IP Rating: IP65, Suitable for wet locations

CERTIFICATIONS:



MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
CRE-08-30K-BR	10W(2.5W X 4)	100~277ACV	900LM	3000K
CRE-08-40K-BR	10W(2.5W X 4)	100~277ACV	900LM	4000K
CRE-08-50K-BR	10W(2.5W X 4)	100~277ACV	900LM	5000k
CRE-08-30K-SIL	10W(2.5W X 4)	100~277ACV	900LM	3000K
CRE-08-40K-SIL	10W(2.5W X 4)	100~277ACV	900LM	4000K
CRE-08-50K-SIL	10W(2.5W X 4)	100~277ACV	900LM	5000k

LIGHTING SPECIFICATIONS:

- LED: Philips Lumileds LEDs
- Total lumens: 900LM
- Color temperature: 3000K/4000k/5000k
- Color rendering index: >70


WARRANTY: 7 years



CRE-08-30K-BR **CRE-08-30K-SIL**
CRE-08-40K-BR **CRE-08-40K-SIL**
CRE-08-50K-BR **CRE-08-50K-SIL**

CREST BY WESTGATE LED WALL SCONCES

PHOTOMETRICS CHART :

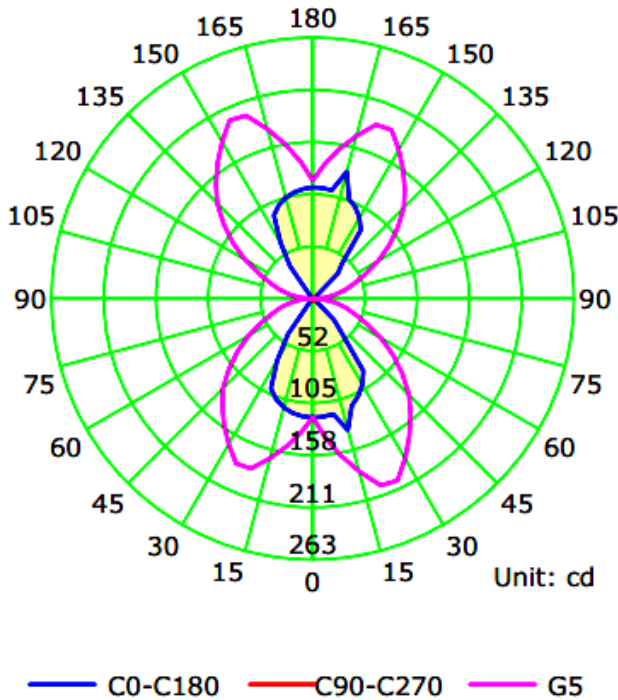

MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
CRE-08-30K-BR	10W(2.5W X 4)	100~277ACV	900LM	3000K
CRE-08-40K-BR	10W(2.5W X 4)	100~277ACV	900LM	4000K
CRE-08-50K-BR	10W(2.5W X 4)	100~277ACV	900LM	5000k
CRE-08-30K-SIL	10W(2.5W X 4)	100~277ACV	900LM	3000K
CRE-08-40K-SIL	10W(2.5W X 4)	100~277ACV	900LM	4000K
CRE-08-50K-SIL	10W(2.5W X 4)	100~277ACV	900LM	5000k

The Average Illuminance Effective Figure

