





**DIMENSIONS:**

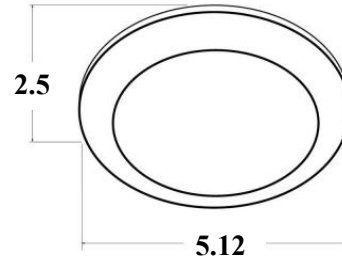

H 5" x W 5" x D 2"

DLS4-27K DLS4-30K  
DLS4-41K DLS4-50K

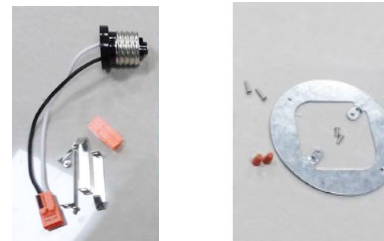

Recessed Mounting Surface Mounting

**LED Disc Downlight 4"**

Universal surface mount  
Fits most J-boxes & 5"/6" recessed housings  
New direct A/C technology does not require an LED driver,  
contributes to longer life and generates less heat.  
Rated for wet location.  
Saves up to \$452.22

**ELECTRICAL SPECIFI-**

- Working voltage: 120V AC
- Watts: 9W
- CRI: 90
- Power factor: 90% +

**LIGHTING SPECIFICA-**

- Fully dimmable
- Lumens: 600
- Beam angle: 120°
- LED: Epistar —35,000 hour design life
- Lens: Translucent acrylic
- Color temperature: 2700K and 3000K

MOD-EL	DIAM-ETER	WAT-TS	VOLT-AGE	LU-MENS	COLOR-TEMP
DLS4-27K	4"	9W	120V AC	550~600	WW 2700K
DLS4-30K	4"	9W	120V AC	550~600	WW 3000K
DLS4-41K	4"	9W	120V AC	550~600	NW 4100K
DLS4-50K	4"	9W	120V AC	550~600	DL 5000K

**HOUSING**

- Finish: White powder coat
- Housing: Spun aluminum
- Trim ring: Integrated spun aluminum white powder coat finish
- Gasket: Neoprene foam gasket
- Suitable for damp locations
- Maximum ambient 4°C (104°F)

**CERTIFICATIONS:** UL listed, Energy Star-

**WARRANTY: 5 years 50,000 hour life**

