


JOB NAME: _____

DATE: _____

TYPE: _____



DIMENSIONS:

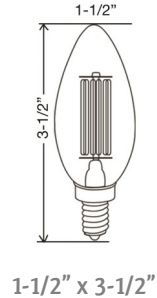

E12-FLA-5W-27K-D
E12-FLA-5W-40K-D

LED Candelabra

Westgate's dimmable LED lamp technology provides a soft, even illumination without hot spots or LED imaging. Our compact size and excellent thermal management make Westgate LED lamps the choice of professionals.

MODEL NO	WATT	LUMENS	BEAM	VOLTAGE	COLOR
E12-FLA-5W-27K-D	5W	400	360°	120V	WW2700K
E12-FLA-5W-40K-D	5W	400	360°	120V	NW 4000K

ELECTRICAL SPECIFICATIONS:

- Voltage: 110 - 130 V
- Wattage: 5watts
- Energy-efficiency label (EEL): A++
- Emits no UV/IR light

LIGHTING SPECIFICATIONS:

- Dimmable: Yes 10 - 100%
- Lumens: 400 lm
- CRI: >80
- Lifespan: 25,000 Hours
- Color: 2700K (Warm white) and 4000K (Natural white)
- Beam Angle: 360°
- Base: E12 Candelabra

SPECIAL FEATURES:

- Finish: Clear
- Long life-reduced re-lamping cost
- Contains no mercury

WARRANTY:

- Five-year warranty

CERTIFICATIONS:

- UL + FCC

