

JOB NAME: _____


DATE: _____

TYPE: _____



DIMENSIONS:

8-1/2"(L) x 5-3/4"(W) x 4-1/2"(D)

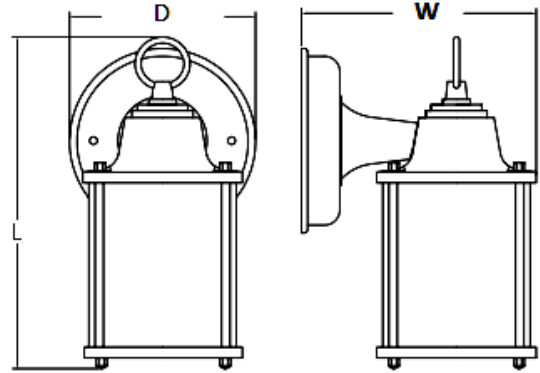

LRS-B-30K-PC
LRS-B-40K-PC

LED RESIDENTIAL LANTERNS WITH PHOTOCELL

Ideal for general site lighting, residential houses, doorway, pathway and garages

ELECTRICAL SPECIFICATIONS:

- Voltage: 120ACV, 60 Hz
- Wattage: 6W
- Power Factor: 0.95
- Efficacy: 91LM/W

HOUSING SPECIFICATIONS:

- Aluminum housing with powder coated
- Includes pre-wired photocell
- Operating temperature: -40°F to 104°F
- Lifespan: 50,000 hr.
- IP Rating: IP65

CERTIFICATIONS:ETL



MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
LRS-B-30K-PC	6W	120ACV	550LM	3000K
LRS-B-40K-PC	6W	120ACV	550LM	4000K

LIGHTING SPECIFICATIONS:

- LED: DOB
- Total lumens: 550LM
- Color temperature: 3000K/4000k
- Color rendering index: >80

WARRANTY: 7 years

