




DIMENSIONS:

47.24"(L) x 2.62"(W) x 2.7(H)

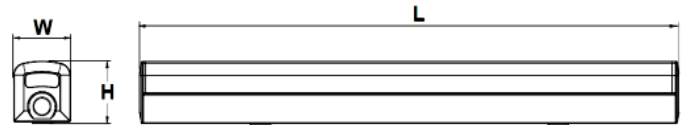

LSS-4FT-32W-MCT

LED MULTI COLOR TEMPERATURE STRIP LIGHT

Ideal for one-for-one replacement of conventional lighting systems such as HID and fluorescent. Applications include manufacturing, warehousing and other large indoor spaces

ELECTRICAL SPECIFICATIONS:

- Voltage: 120~277 VAC/50~60 Hz
- Wattage: 32W
- Efficacy: 130LM/W

HOUSING SPECIFICATIONS:

- Linkable
- Mounting: Ceiling Mount, Suspension Mount
- Operating temperature: -40°F ~ 122°F
- Suitable for Damp locations

CERTIFICATIONS: UL, DLC



| MODEL | WATTS | VOLTAGE | LUMENS | COLOR TEMP |
|-----------------|-------|-------------|--------|------------|
| LSS-4FT-32W-MCT | 32W | 100~277V AC | 4160LM | MCT |

OPTIONAL ACCESSORIES:



| MODEL | DESCRIPTION |
|-----------|---|
| LSS-CB | COUPLING BRACKET |
| SCL-CS | ADJ. 1/16" 6FT. SUSPENSION KIT WITH SINGLE-CONNECTOR KEY HOLE SET + 2 T-BAR CLIPS + 1 CABL BUSHING + 3 PLASTIC TIE STRAPS |
| SCL-GSY10 | HEAVY-DUTY ADJUSTABLE 10 FT. 1/16" SUSPENSION KIT WITH Y-CONNECTOR & LOOP GRIPPER & HOOKS |
| SCL-GSY20 | HEAVY-DUTY ADJUSTABLE 20 FT. 1/16" SUSPENSION KIT WITH Y-CONNECTOR & LOOP GRIPPER & HOOKS |

LIGHTING SPECIFICATIONS:

- Dimming: 0~10V dimmable
- Total lumens: 4160LM
- Color temperature: MCT(3500K,4000K,5000K)

WARRANTY: 5 years

