


DIMENSIONS:

14"(W) x 9-1/4"(H) x 8-1/4"(D)

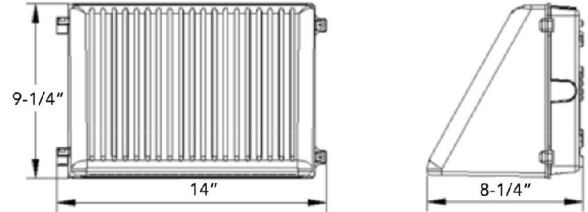

LWP2-80-CW LWP2-80-WW

LED CUTOFF WALL PACK

Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas.

ELECTRICAL SPECIFICATIONS:

- Voltage: 120-277VAC 50/60Hz
- Wattage: 80W
- Other wattages: 50W (Non-Dimmable)
- Power factor: >0.95
- Efficacy: 100LM/W~112.5LM/W

HOUSING SPECIFICATIONS:

- Die cast aluminum
- Outdoor powder coat finish (Dark Bronze)
- Operating temperature: -4°F ~ 104°F
- Lifespan: 70000 Hrs.
- IP rating: IP65, Wet Locations
- TIR Optic lens—Type II
- Full cutoff, dark sky compliant

CERTIFICATIONS: UL, DLC



MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
LWP2-80-CW	80W	120~277V AC	9000 LM	5000K
LWP2-80-WW	80W	120~277V AC	8000 LM	3000K

LIGHTING SPECIFICATIONS:

- LED type/brand: Philips Lumileds / SMD 3030
- Total lumens: 8000LM and 9000LM
- Color temperature: 4000K / 5000K
- Color rendering index: >80

WARRANTY: 7 years

