


DIMENSIONS:

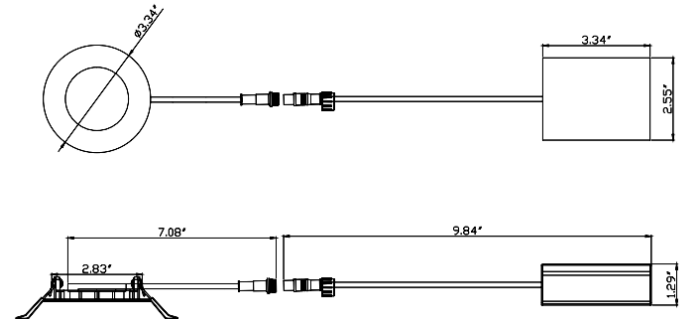

Junction box 1" thick included with fixture

1/4" (Thick)



- RSL3-27K RSL3-30K
- RSL3-30K-BN RSL3-30K-ORB
- RSL3-40K RSL3-50K
- RSL3-MCT RSL3-MCT-BN
- RSL3-MCT-ORB

LED ULTRA SLIM RECESSED LIGHTS

Ideal for New as well as old residential and commercial constructions.

ELECTRICAL SPECIFICATIONS:

- Voltage: 120VAC
- Wattage: 6W
- Power factor: >0.90
- Efficacy: 66LM/W, 70LM/W

HOUSING SPECIFICATIONS:

- 1/4" Thick
- Die-cast Aluminum with white powder coat finish
- Pot light housing is not required even for insulated ceiling
- Junction box 1" thick included with fixture
- Type IC rated: Approved for direct contact with insulation
- Operating temperature: -40°F ~ 104°F
- Lifespan: 50,000 Hrs.
- Air-tight and damp location approved

CERTIFICATIONS: ETL,ES



WARRANTY: 5 years

| MODEL | WATTS | VOLTAGE | LUMENS | COLOR TEMP |
|---|-------|---------|--------|------------|
| RSL3-27K | 6W | 120VAC | 400LM | 2700K |
| RSL3-30 | 6W | 120VAC | 400LM | 3000K |
| RSL3-30K-BN (Brushed Nickel Finish) | 6W | 120VAC | 400LM | 3000K |
| RSL3-30K-ORB (Oil-Rubbed Bronze Finish) | 6W | 120VAC | 400LM | 3000K |
| RSL3-40K | 6W | 120VAC | 420LM | 4000K |
| RSL3-50K | 6W | 120VAC | 420LM | 5000K |
| RSL3-MCT | 6W | 120VAC | 420LM | MCT |
| RSL3-MCT-BN | 6W | 120VAC | 420LM | MCT |
| RSL3-MCT-ORB | 6W | 120VAC | 420LM | MCT |

OPTIONAL ACCESSORIES:



RSL-EXT-10FT



RSL3-RI

| MODEL | DESCRIPTION |
|--------------|--|
| RSL-EXT-10FT | 10 Ft. Extension Cable For use with all Slim Light |
| RSL3-RI | 3" Round Rough-in Plate, 26" long |

LIGHTING SPECIFICATIONS:

- Dimming: dimmable
- Lens: 0.125" white translucent acrylic
- Optics: White translucent acrylic
- LED: Seoul DOB (Driver On Board) Technology
- Total lumens: 400LM/420LM
- Color temperature: 2700K/3000K/4000K/5000K /MCT(3000K,4000K,5000K)
- Color rendering index: >80
- Beam Angle: 100° -110°



JOB NAME: _____

DATE: _____

TYPE: _____

RSL3-27K RSL3-30K
 RSL3-30K-BN RSL3-30K-ORB
 RSL3-40K RSL3-50K
 RSL3-MCT RSL3-MCT-BN
 RSL3-MCT-ORB

LED ULTRA SLIM RECESSED LIGHTS

| MODEL | WATTS | VOLTAGE | LUMENS | COLOR TEMP |
|---|-------|---------|--------|------------|
| RSL3-27K | 6W | 120VAC | 400LM | 2700K |
| RSL3-30 | 6W | 120VAC | 400LM | 3000K |
| RSL3-30K-BN (Brushed Nickle Finish) | 6W | 120VAC | 400LM | 3000K |
| RSL3-30K-ORB (Oil-Rubbed Bronze Finish) | 6W | 120VAC | 400LM | 3000K |
| RSL3-40K | 6W | 120VAC | 420LM | 4000K |
| RSL3-50K | 6W | 120VAC | 420LM | 5000K |
| RSL3-MCT | 6W | 120VAC | 420LM | MCT |
| RSL3-MCT-BN | 6W | 120VAC | 420LM | MCT |
| RSL3-MCT-ORB | 6W | 120VAC | 420LM | MCT |

BRAND OF DIMMERS:

| NO. | BRAND | MODEL |
|-----|----------------|----------------|
| 1 | Leviton | 6631-1LT |
| 2 | Lutron | MACL-153MLH-AL |
| 3 | Lutron | TGCL-153PH-LA |
| 4 | Lutron | DVW-603PGH-WH |
| 5 | Lutron | CT-600PR-WH |
| 6 | Lutron | LGCL-153PHL-IV |
| 7 | Lutron | TGCL-153PH-LA |
| 8 | Lutron | LSLV603PWV |
| 9 | Leviton | 6674-POW |
| 10 | Lutron | DVCL-153P |
| 11 | Lutron | MSCL-OP153P |
| 12 | Lutron | CTCL-153P |
| 13 | Lutron | MACL-153M |
| 14 | Pass & Seymour | HCL453PTCCCV6 |
| 15 | Pass & Seymour | LSLV603PWV |

