 




DIMENSIONS:

47.12"(L) x 0.9"(W) x 1.35"(H)



- T5-12IN-5W-50K-D
- T5-12IN-5W-40K-D
- T5-12IN-5W-30K-D

LED T5 RETROFIT BAR WITH INTERNAL DRIVER

Ideal for retrofitting T5 & T8 high bays, tro lers, and other linear fixtures.

ELECTRICAL SPECIFICATIONS:

- Voltage: 100-277VAC 50/60Hz
- Wattage: 5W
- Max Run: 31'
- Power factor: >0.90
- Efficacy: 115~125LM/W

HOUSING SPECIFICATIONS:


- Linkable fixture
- Internal isolated power supply
- Mounting: Surface mount.
- Operating temperature: -4°F ~ 104°F
- Lifespan: 50,000 hrs.
- IP rating: IP20

CERTIFICATIONS:



MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
T5-12IN-5W-50K-D	5W	120~277VAC	625LM	5000K
T5-12IN-5W-40K-D	5W	120~277VAC	575LM	4000K
T5-12IN-5W-30K-D	5W	120~277VAC	575LM	3000K

OPTIONAL ACCESSORIES:

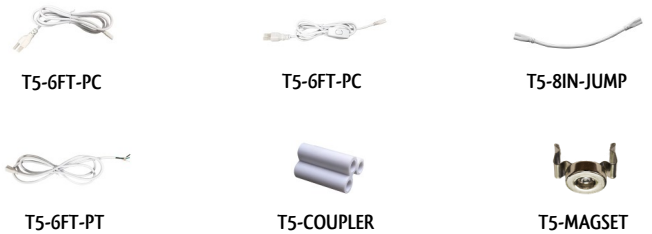

MODEL	DESCRIPTION
T5-6FT-PC	6' Plug-in Power Cord
T5-6FT-PCS	6' Plug-in Power Cord with Switch
T5-8IN-JUMP	8" Jumper Cord
T5-6FT-PT	6' AC Input Wire
T5-COUPLER	End-to-End Coupler
RT5-MAGSET	Clip-on Secure Magnet Set

LIGHTING SPECIFICATIONS:

- LED SMD type: LM80 2835
- Lens: Frosted Lens
- Total lumens: 625LM/575LM
- Color temperature: 5000K/4000K/3000K
- Color rendering index: >80
- Beam Angle: 140°

WARRANTY: 5 years

