

JOB NAME: \_\_\_\_\_


DATE: \_\_\_\_\_

TYPE: \_\_\_\_\_



**DIMENSIONS:**

12"(L) x 1"(H) x 4"(D)

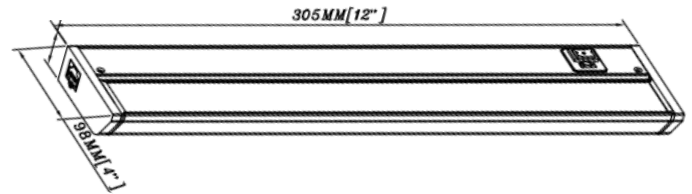

**UCA-12-WHT**  
**UCA-12-BRZ**

**120-VOLT LED UNDERCABINET**

Ideal for under cabinet, display cases, or in low-profile areas. UCA offers low heat, easy installation, environmentally friendly and maintenance free for many years.

**ELECTRICAL SPECIFICATIONS:**

- Working Voltage: 120V (Internal Driver)
- Wattage: 5 W
- Efficacy: 55 LM/W

**HOUSING SPECIFICATIONS:**

- Linkable
- 3/4" KOs for hardwiring installation (multiple on top and back)
- Built-in LED driver
- 22- gauge sheet metal housing, white/bronze enamel finish, painted after fabrication
- Very low, 1" profile, only 3-1/2" wide
- Tempered glass lens for easy cleaning inside frosted to reduce LED imaging
- 120V with plug and hardwire option included
- Color packaging with hanging tab
- 3/8" flex connector and mounting screws included
- Includes 6' power cord with plug and (1) 8" interconnect cable
- Key-holed mounting slots in housing simplify installation



6' Power Cord  
8' interconnect cable  
End-to-End connector  
Mounting screws



On/Off Switch with  
100%/50% Dimming  
Color Temp. Switch:  
2700K/3000K/4000K



3/4" KOs  
Cable Connector Included

MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
UCA-12-WHT	5W	120V	275 LM	2700K/3000K/4000K
UCA-12-BRZ	5W	120V	275 LM	2700K/3000K/4000K

**LIGHTING SPECIFICATIONS:**

- Lens: Tempered glass lens
- Total lumens: 275 LM
- Adjustable color temperature(2700K/3000K/4000K)
- Color rendering index: 84

**WARRANTY: 5 years**

**CERTIFICATIONS:**

