


DIMENSIONS:

18-1/2"(W) x 9"(H) x 8-1/2"(D)

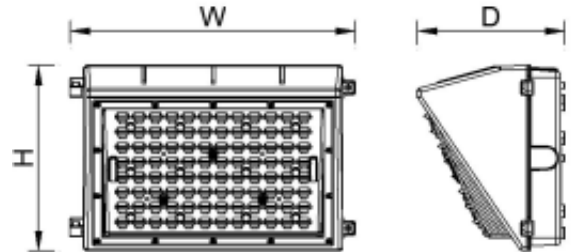

Bottom LED array ensures seamless coverage in proximity of the fixture



WML2-120W-50K-HL-LG
WML2-120W-40K-HL-LG
WML2-120W-30K-HL-LG

LED NON-CUTOFF 2nd GENERATION WALL PACK

Ideal for general site lighting, alleys, loading docks, doorway, pathway, and parking areas.

ELECTRICAL SPECIFICATIONS:

- Voltage: 120~277 VAC/60 Hz
- Wattage: 120 W
- Power factor: 0.95
- Efficacy: 132 LM/W

HOUSING SPECIFICATIONS:

- Die-cast aluminum housing
- Powder Coat finish (Dark Bronze)
- Same footprint as traditional HID wall packs
- Includes mounting hardware
- Four 1/2" hubs: 1 top, 1 on each side, 1 rear.
- Operating temperature: -40°F to 104°F
- Lifespan: 70,000 hr.
- IP Rating: IP65

CERTIFICATIONS: UL, DLC



LIGHTING SPECIFICATIONS:

- Dimming: 0~10V dimmable
- Lens: Polycarbonate Optic Lens
- LED Chip: Philips Lumileds LEDs
- Total lumens: 15900 LM
- Color temperature: 5000K/4000K/3000K
- Color rendering index: >80

WARRANTY: 7 years

MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
WML2-120W-50K-HL-LG	120W	120~277 VAC	15900 LM	5000K
WML2-120W-40K-HL-LG	120W	120~277 VAC	15900 LM	4000K
WML2-120W-30K-HL-LG	120W	120~277 VAC	15900 LM	3000K

