


DIMENSIONS:

15.06"(W) x 9.29"(H) x7.46"(D)

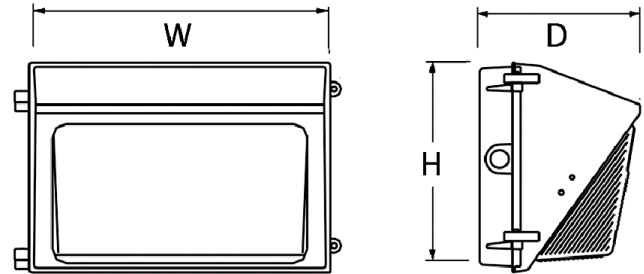

WML-HL-50W-50K
WML-HL-50W-40K
WML-HL-50W-30K

LED NON-CUTOFF WALL PACK

Ideal for general site lighting, alleys, loading docks, doorway, pathway and parking areas. Provides crisp, directional light.

ELECTRICAL SPECIFICATIONS:

- Input Wattage: 50W
- Input Voltage: 120-277VAC 50/60Hz
- Input current: 0.52A
- Power factor: >0.9
- Efficacy: 142LM/W

HOUSING SPECIFICATIONS:

- Die-cast aluminum with powder coat finish (Dark Bronze)
- Same footprint as traditional HID wall packs
- Four 1/2" hubs: 1 top, 1 on each side, 1 rear
- Mounting: Wall Mounting
- Operating temperature: -4°F ~ 104°F
- Lifespan: 70000 Hrs.
- IP rating: IP64, Wet Locations

CERTIFICATIONS: UL, DLC



MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
WML-HL-50W-50K	50W	120~277V AC	7100LM	5000K
WML-HL-50W-40K	50W	120~277V AC	7070LM	4000K
WML-HL-50W-30K	50W	120~277V AC	7040LM	3000K

LIGHTING SPECIFICATIONS:

- Dimming: No
- Lens: Prismatic borosilicate glass lens
- Chip: LUMILEDS LED
- Total lumens: 7040LM/7070LM/7100LM
- Color temperature: 3000K/4000K/5000K
- Color rendering index: >80

WARRANTY: 7 years



WML-HL-50W-50K
WML-HL-50W-40K
WML-HL-50W-30K

LED NON-CUTOFF WALL PACK

PHOTOMETRIC:

MODEL	WATTS	VOLTAGE	LUMENS	COLOR TEMP
WML-HL-50W-50K	50W	120~277V AC	7100LM	5000K
WML-HL-50W-40K	50W	120~277V AC	7070LM	4000K
WML-HL-50W-30K	50W	120~277V AC	7040LM	3000K

