



JACKSON[®]




SAFETY

TECHNICAL DATA SHEET

F10 PETG Face Shields

New Code	Old Code	Shade	Dimensions	Shape	Bound	Case Count
28107		Clear—AF	8" x 15.5" x .035"	E	Unbound	96
29104	3005399	Clear	8" x 15.5" x .040"	E	Unbound	100
29101	3005385	Medium Green	8" x 15.5" x .040"	E	Unbound	36
28962	3029190	Clear	9" x 15.5" x .040"	D	Bound	50
28963	3029191	Clear	9" x 15.5" x .040"	D	Unbound	50
28764 ¹		Clear—AF	8" x 15.5" x .035"	N	Unbound	96
28765 ¹	3005392	Clear	6" x 15.5" x .040"	N	Unbound	36

Property	Description
Standards	Meets ANSI Z87.1 2010 Standards
Application	Splash, light industrial manufacturing, landscaping, food processing
Materials	PETG

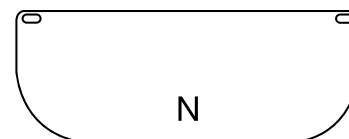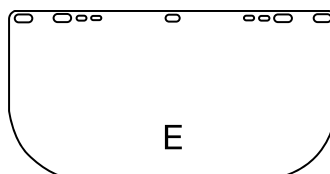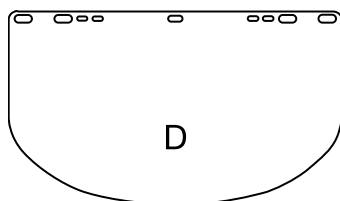

WARNING: Application & Safety

Face shields do not provide unlimited eye and face protection— primary eye protection (safety eyewear or goggles) must be worn. Face shields recommended for use only with Jackson Safety[®] head gear/cap adapters.

Workmanship Requirement

Face shields shall be made in accordance with reasonable industry practice with respect to defects or dirt and contamination. Face shields should be packaged as specified having described shape, dimension and color in the appropriate quantity as listed.

¹ Face Shield 28764 and 28765 only work with C10 Bump Caps that have the face shield attachment.
Face Shield 28765 does not meet ANSI Z87.1 2010 Standards.

For additional information: 1-800-323-7402 or sales.usa@surewerx.com