


Project Name

Location

Prepared By

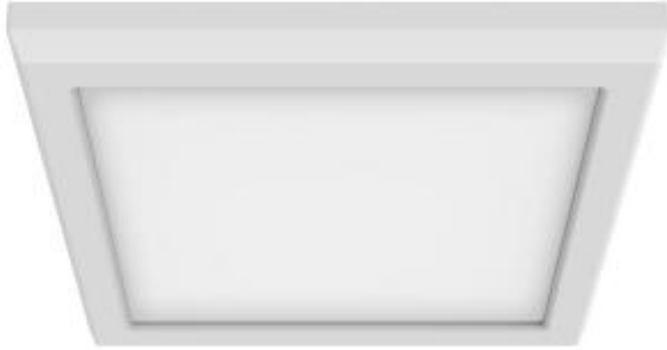

## NUVO 62-1714

11W LED 7" SQ WHITE

### Notes

[www] 05-15-2023 01:50:04

### General

Status	Active
Fixture Type	Flush Mount
Finish	White
Wattage	11W
Lumen Output	940L-1000L
CCT (Kelvin)	2700K/3000K/3500K/4000K/5000K
Indoor or Outdoor Fixture	Indoor

### Specifications

Technology	LED
Color Temperature	Warm to Cool White
CRI	90
Voltage	120V
Beam Angle	100
Rated Hours	50000
Operating Temperature	-20C (-4F) to +40C (+104F)
Dimmable	Yes-Dimmable
Dimming Note	120V only
Lens Material	Poly methyl methacrylate (PMMA)
Surge Protection	Built-in surge protection - 2.5KV
Weight (lb.)	1.04
Material	Die Cast Aluminum

### Dimensions

Height (in.)	0.67
Width (in.)	7.00
Length (in.)	7.00

### Compliance

Safety Listing	cETLus
Location Rating	Wet
Energy Star	Yes
ES Unique ID	ESID-2402976
CA T20 / T24 Rationale	California T24 2016 - 2022 JA8 Listed
California Status	Lawful for sale in California
Title 20 / 24 Status	California T24 Listed
California Prop 65	Lead
RoHS Compliant	Yes
NEC Compliance	Clothes Closet Certified - Reg: 410.16 (A)(3) and 410.16 (C)(5)
FCC Compliant	Yes
Flicker Free	No
SDS Sheet	LED_Fixture

### Additional Information

Additional Information	UGR - 26.13; SDCM - 464; Hi pot - DC-1550V; Edge-lit - Yes
Specification Note	Overall height of fixture and driver: 1.59"
Installation Notes	Surface mount; Compatible with 3" & 4" J-box and pancake J-box with additional accessory
Warranty	5 Year Limited - Fixtures

